

Beam Attachment Kit



FUNKTIONER

For installations where the cable cannot be looped around the steel beam

Can support two catenary systems using each eye nut as an anchoring point

Kit includes beam clamps and eye nuts

Installs on top or bottom flange of I-beams or bar joists

SPECIFIKATIONER

Table 1/2

Katalognummer	Artikelnummer	Materiale	Finish	Flange Thickness (FT)	Rod Size (RS)	Static Load 1 (F1)
SLBM12	196852	Stål	Electrogalvanized, Hot-Dip Galvanized	10 - 20 mm	12	400N


Table 2/2

Katalognummer	Artikelnummer	Static Load 2 (F2)	Static Load 3 (F3)
SLBM12	196852	700N	800N

YDERLIGERE PRODUKTOPLYSNINGER

Static load 1 represents a point load in the center of the catenary installation. Static load 2 represents a two or three point distributed load on the catenary installation. Static load 3 represents a four or more point distributed load on the catenary installation.

DIAGRAMS

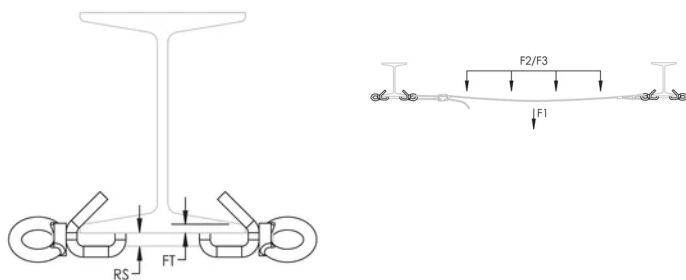

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

