


Beam Clamp with Swivel

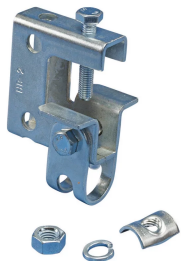

CERTIFICERINGER



FUNKTIONER

Swivel beam clamp

Suitable for mounting onto sloped steel structures

Includes M10 nut and washer

SPECIFIKATIONER

Materiale: Stål


Table 1/1

Katalognummer	Artikelnummer	Finish	Flange Thickness (FT)	Torque (TQ)	Angle 1 (a1)	Angle 2 (a2)
HB2	336030	Electrogalvanized	24 mm Max	6 N·m	45 ° Min	30 ° Max
HB2HD	336040	Hot-Dip Galvanized	24 mm Max	6 N·m	45 ° Min	30 ° Max

YDERLIGERE PRODUKTOPLYSNINGER

Setscrew must be tightened and torqued onto the sloped side of the I-beam.

DIAGRAMS

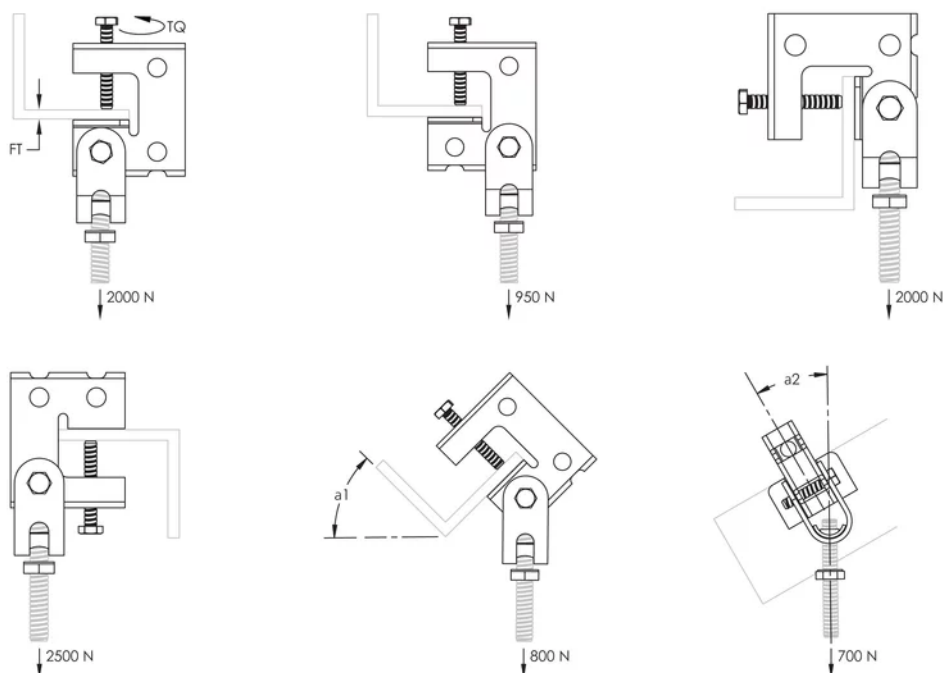

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

