

Branch Line Restraint Pipe Attachment



CERTIFICERINGER



FUNKTIONER

Accepts 3/8" or 1/2" (M10 or M12) threaded rod

Quick grip clamp simplifies measuring and cutting of threaded rod

Eliminates need to cut threaded rod to exact dimensions

Works with rough-cut threaded rod and eliminates pipe-side deburring

Can be installed with threaded rod above or below the service pipe

Shear-off head helps ensure correct torque and simplifies inspection

SPECIFIKATIONER

Finish: Electrogalvanized

Materiale: Stål

Table 1/2


Katalognummer	Artikelnummer	NB/DN	Outer Diameter (OD)	Rod Size (RS)	Height (H)	Length (L)
CSBBRP0200EG	404480	50	60.3 mm	10, 12	100.3 mm	68.3mm

Katalognummer	Artikelnummer	NB/DN	Outer Diameter (OD)	Rod Size (RS)	Height (H)	Length (L)
CSBBRP0125EG	404478	32	42.2 mm	10, 12	82.6 mm	50mm
CSBBRP0100EG	404477	25	33.4 mm	10, 12	73.7 mm	41.4mm
CSBBRP0150EG	404479	40	48.3 mm	10, 12	88.9 mm	56.1mm

Table 2/2

Katalognummer	Artikelnummer	Width (W)
CSBBRP0200EG	404480	22.2 mm
CSBBRP0125EG	404478	22.2 mm
CSBBRP0100EG	404477	22.2 mm
CSBBRP0150EG	404479	22.2 mm

DIAGRAMS

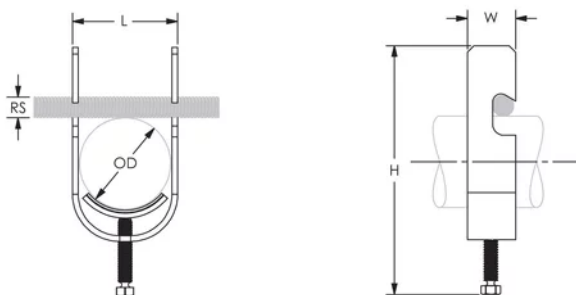

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRachte

