

Branch Line Restraint Structure Attachment to Steel



CERTIFICERINGER



FUNKTIONER

Swivel barrel nut accepts 3/8" or 1/2" (M10 or M12) threaded rod

Attaches to steel members with self-drilling/tapping screw

SPECIFIKATIONER

Table 1/2

Katalognummer	Artikelnummer	Materiale	Finish	Rod Size (RS)	Flange Thickness (FT)	Height (H)
CSBBRS1MEG	402239	Stål	Electrogalvanized	10, 12	2.7 - 12.7 mm	28.2 mm


Table 2/2

Katalognummer	Artikelnummer	Length (L)	Width (W)	Screw Diameter (Sc)	Screw Length (L)
CSBBRS1MEG	402239	40.4mm	26.9 mm	2.7 mm	32mm

YDERLIGERE PRODUKTOPLYSNINGER

Branch line structural attachments are for restraint only and not for the hanging of fire sprinkler piping.

DIAGRAMS

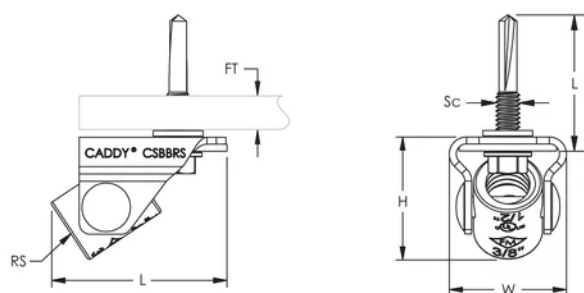

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

