

Cable Tie with Flange Clip



CERTIFICERINGER



FUNKTIONER

Used to support cables from beam flanges

Requires only a hammer to install

Comes complete with zip-tie

SPECIFIKATIONER

Table 1/2

Katalognummer	Artikelnummer	Materiale	Finish	Flange Thickness (FT)	Cable Tie	Diameter (Ø)
2H4CTBB	170210	Spring Steel	nVent CADDY Armour	2 - 3 mm	Nylon Black	10 - 70 mm
2H4CTBW	170170	Spring Steel	nVent CADDY Armour	2 - 3 mm	Nylon White	10 - 70 mm
4H24CTBW	170180	Spring Steel	nVent CADDY Armour	3 - 8 mm	Nylon White	10 - 70 mm
4H24CTBRS1	170280	Stainless Steel 301 (EN 1.4310)		3 - 8 mm	Stainless Steel 302 (EN 1.4324)	25 - 51 mm


Katalognummer	Artikelnummer	Materiale	Finish	Flange Thickness (FT)	Cable Tie	Diameter (Ø)
4H24CTBB	170220	Spring Steel	nVent CADDY Armour	3 - 8 mm	Nylon Black	10 - 70 mm
4H58CTBW	170190	Spring Steel	nVent CADDY Armour	8 - 14 mm	Nylon White	10 - 70 mm
4H58CTBB	170240	Spring Steel	nVent CADDY Armour	8 - 14 mm	Nylon Black	10 - 70 mm
4H58CTBRS1	170300	Stainless Steel 301 (EN 1.4310)		8 - 14 mm	Stainless Steel 302 (EN 1.4324)	25 - 51 mm
4H912CTBB	170260	Spring Steel	nVent CADDY Armour	14 - 20 mm	Nylon Black	10 - 70 mm
4H912CTBW	170200	Spring Steel	nVent CADDY Armour	14 - 20 mm	Nylon White	10 - 70 mm
4H912CTBRS1	170310	Stainless Steel 301 (EN 1.4310)		14 - 20 mm	Stainless Steel 302 (EN 1.4324)	25 - 51 mm

Table 2/2

Katalognummer	Artikelnummer	Static Load	Certificeringer
2H4CTBB	170210	150N	ITB
2H4CTBW	170170	150N	ITB
4H24CTBW	170180	150N	ITB
4H24CTBRS1	170280	300N	
4H24CTBB	170220	150N	ITB
4H58CTBW	170190	150N	ITB
4H58CTBB	170240	150N	ITB
4H58CTBRS1	170300	300N	
4H912CTBB	170260	150N	ITB

Katalognummer	Artikelnummer	Static Load	Certificeringer
4H912CTBW	170200	150N	ITB
4H912CTBRS1	170310	300N	

DIAGRAMS

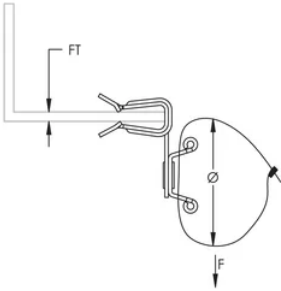

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

