


# Cantilever Arm with E2 Channel

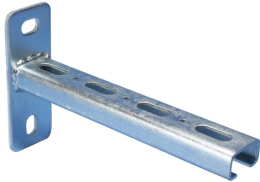

## CERTIFICERINGER



## FUNKTIONER

Perforated, cold rolled

Slotted backplate

## SPECIFIKATIONER

**Finish:** Electrogalvanized

**Materiale:** Stål

Table 1/1

| Katalognummer | Artikelnummer | Length (L) |
|---------------|---------------|------------|
| CE224H0200EG  | 597500        | 200mm      |
| CE224H0300EG  | 597510        | 300mm      |


 
 

**Thickness (T):** 2.4 mm

**E:** 4 mm

**Hole Size (HS):** 5 mm

|                    |            |
|--------------------|------------|
| <b>X:</b>          | 11 x 18 mm |
| <b>Y:</b>          | 11 x 27 mm |
| <b>C:</b>          | 15.5 mm    |
| <b>A:</b>          | 20 mm      |
| <b>B:</b>          | 34 mm      |
| <b>Width (W):</b>  | 40 mm      |
| <b>D:</b>          | 50 mm      |
| <b>Height (H):</b> | 120 mm     |

## DIAGRAMS

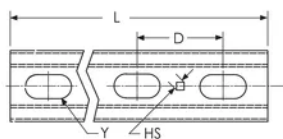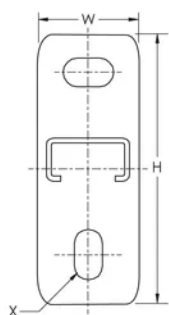

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRachte**

