

Oval Pipe Clamp with Nut, 12, 15 DN, M8, M10 Rod

KATALOGNUMMER

MXOVDN1215EG



FUNKTIONER

Designed to support pre-insulated twin tubes and integrated power cable for solar heat collectors

Shape of clamp provides a stable attachment to wall or ceiling

PRODUKTEGENSKABER

Artikelnummer: 401244

Materiale: Stål

Finish: Electrogalvanized

NB/DN: 12; 15

Rod Size (RS): M8;M10

A: 43 mm

B: 78 mm


Width (W): 20 mm

Thickness (T): 2 mm

Screw Diameter (Sc): 6

Screw Length (L): 20mm

DIAGRAMS

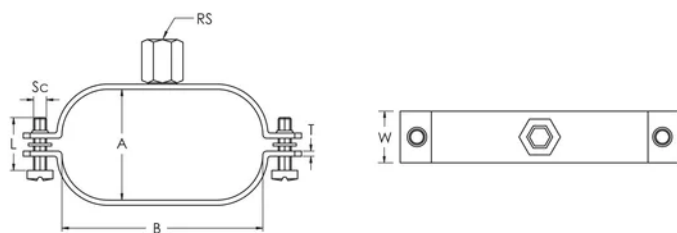

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

