

# Flexible Plastic Conduit and Pipe Clamp



## FUNKTIONER

---

Push-in installation of conduit

Flexible clamping design accommodates multiple conduit sizes using one clamp

Compatible with different structural attachment components to accommodate a variety of structures including concrete, brick, plywood, cable tray, spring steel fasteners and threaded rod

Snap-together clips can be easily assembled to limit the number of fixing points to structure

Low profile allows for installations in tight spaces

Non-flame propagating per IEC 61386-25

Passed 650°C glowing/hot-wire test per EN 60695-2

Suitable for insulated and non-insulated pipe applications

Push-in installation of conduit

Halogen free

UV-stabilized


Compliance to AS3500

Withstands up to 40kg of extraction force

## SPECIFIKATIONER

---

## DIAGRAMS

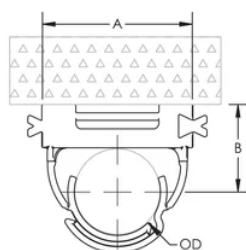

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

