


# Improved nVent CADDY Cat HP J-Hook Mod Clip with BC Beam Clamp

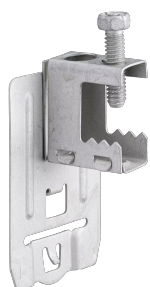

The Improved nVent CADDY Cat HP Mod Clip J-Hook with BC Beam Clamp simplifies beam flange installation with an easy-to-use design. By eliminating the need for screws, rivets or special tools during assembly, installation time and cost is reduced. A simple clip onto nVent CADDY Cat HP components ensures a secure hold—ultimately enhancing rigidity and stability while minimizing inventory impact and providing flexibility on the job site.

## CERTIFICERINGER



## FUNKTIONER


Easy beam flange installation

Works with nVent J-Hook Versa-Mount technology from nVent CADDY

## SPECIFIKATIONER

Table 1/1

| Katalognummer | Artikelnummer | Finish                                | Materiale         | Flange Thickness (FT) | Static Load |
|---------------|---------------|---------------------------------------|-------------------|-----------------------|-------------|
| CATHPMBC      | 186078        | Electrogalvanized, nVent CADDY Armour | Stål, Spring Stål | 16 mm Max             | 440N        |

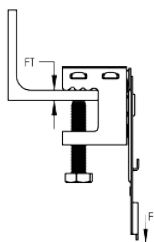

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**

