


Improved nVent CADDY Cat HP J-Hook Mod Clip with BC Beam Clamp, Swivel

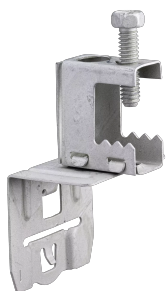

The Improved nVent CADDY Cat HP Mod Clip J-Hook with BC Swivel Beam Clamp offers both easy beam flange installation and 360-degree rotation for versatile cable routing. By eliminating the need for screws, rivets or special tools during assembly, installation time and cost is reduced. A simple clip onto nVent CADDY Cat HP components ensures a secure hold—ultimately enhancing rigidity and stability while minimizing inventory impact and providing flexibility on the job site.

CERTIFICERINGER



FUNKTIONER

Rotates 360 degrees to support various directional runs of cable


Works with nVent J-Hook Versa-Mount technology from nVent CADDY

SPECIFIKATIONER

Table 1/1

Katalognummer	Artikelnummer	Finish	Materiale	Flange Thickness (FT)	Static Load
CATHPMBCB	186079	Electrogalvanized, nVent CADDY Armour	Stål, Spring Stål	16 mm Max	267N

DIAGRAMS

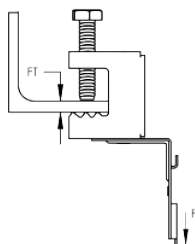

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

