

KP T-Bolt for C-Channel E4



FUNKTIONER

For use with C-Profiles

Pre-mounted with large washer and nut

SPECIFIKATIONER

Channel Type: E4
Finish: Electrogalvanized
Materiale: Stål

Table 1/1


Katalognummer	Artikelnummer	Screw Diameter (Sc)	Screw Length (L)	A	B
KP3810035	590207	10	35mm	30 mm	23 mm
KP3808040	590210	8	40mm	30 mm	23 mm

YDERLIGERE PRODUKTOPLYSNINGER

Sliding force F2 is limited to 600 N for all types of Nuts and T-Bolts for C-channel System.

Nuts and T-Bolts for C-channel System	
C-Channel Type	Pullout Force F1
E4	2600 N

DIAGRAMS

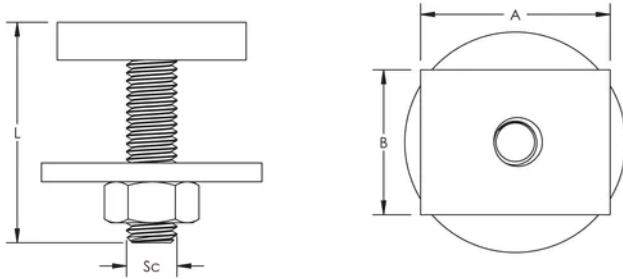

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

