

Light Duty Push-In Anchor



CERTIFICERINGER



R30 - R120

FUNKTIONER

Ideal for use with fire rated clips and clamps

Tool-free push-in installation after hole has been drilled into the concrete

Fire resistance class R30-R120 for design of anchorages under exposure to fire

ETA assessed for anchoring in cracked and non-cracked concrete

SPECIFIKATIONER

Table 1/1

Katalognummer	Artikelnummer	Materiale	Drill Hole Depth	Hole Size (HS)	A
SCMDSN	800070	Stainless Steel 301 (EN 1.4310)	36mm	6 mm	10 mm Max

YDERLIGERE PRODUKTOPLYSNINGER

Drill Hole Depth represents the maximum depth and should be adjusted based on the thickness of product being fixed.


The maximum load per fixing point for multiple use for non-structural applications may, depending on national regulations, be below the approved load of the anchor. The approved loads per fixing point are regulated for their respective countries in

the ETAG 001, Part 6.

Total safety factor as per ETAG 001 included (Y_m and Y_f).

Extract from Permissible Service Conditions of ETA-16/0673			
Multiple use for non-structural applications			
Part Number	Cracked Concrete C20/25	Non-Cracked Concrete C20/25	Standard Embedment Depth
SCMDSN	0.032 kN	0.032 kN	35 mm

DIAGRAMS

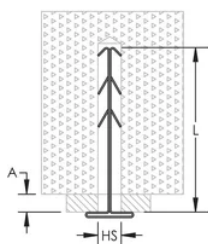

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

