

# nVent CADDY Cat HP J-Hook with Multi-Function Clip



## CERTIFICATION



## FUNCTION

Quick attachment to threaded rod or wire

Fully adjustable and easy to relocate to accommodate changes once installed

Provides optimal support for high-performance data cable, up to and including Cat 5e, Cat 6, Cat 6A, Cat 7 and fibre optic

Provides superior fill capacity and load rating over most other non-continuous cable support alternatives

Rounded edges on J-Hooks provide proper bend radius support for high performance data cables

Cost effective alternative to expensive cable tray

Complies with EN 50174-2

Meets ISO®/IEC 14763-2, ANSI®/TIA 568 and ANSI®/TIA 569

Increased capability and application options by combining 4Z and 6Z products into one enhanced and efficient offering

Improved multi-function clip allows for optimized inventory while reducing job site scheduling risks associated with multiple SKUs

## SPECIFICATION

**Finish:** Pregalvanized; nVent CADDY Armour

Table 1/2

| Katalognummer | Artikelnummer | Materiale         | Diameter (Ø) | Area                | Cable Capacity, Cat 5e | Cable Capacity, Cat 6 |
|---------------|---------------|-------------------|--------------|---------------------|------------------------|-----------------------|
| CAT21HP4Z34   | 181258        | Stål, Spring Stål | 33.3 mm      | 1174mm <sup>2</sup> | 50                     | 40                    |
| CAT32HP4Z34   | 181218        | Stål, Spring Stål | 50 mm        | 2561mm <sup>2</sup> | 90                     | 60                    |
| CAT16HP4Z34   | 181217        | Stål, Spring Stål | 25 mm        | 690mm <sup>2</sup>  | 20                     | 15                    |

Table 2/2


| Katalognummer | Artikelnummer | Cable Capacity, Cat 6A | Trådstørrelse | Rod Size (RS) | Static Load |
|---------------|---------------|------------------------|---------------|---------------|-------------|
| CAT21HP4Z34   | 181258        | 25                     | 3.9 - 4.8 mm  | 4, 6, 8, 10   | 130N        |
| CAT32HP4Z34   | 181218        | 35                     | 3.9 - 4.8 mm  | 4, 6, 8, 10   | 130N        |
| CAT16HP4Z34   | 181217        | 10                     | 3.9 - 4.8 mm  | 4, 6, 8, 10   | 130N        |

## YDERLIGERE PRODUKTOPLYSNINGER

Non-continuous supports may not exceed spacing of 5' (1.5 m) per TIA 569-C.9.7 and EN 50174-2.

Cable capacity is calculated based on a 70% fill rate.

## DIAGRAMS

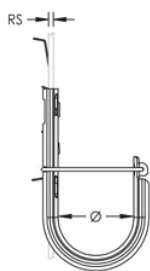

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRachte**

