


# nVent CADDY EZ Riser



The nVent CADDY EZ Riser is a multi-purpose clamp designed to secure and support vertical pipe runs. This unified solution can be installed in several approved orientations and serves as a standard, standoff, or close-quarters riser—effectively functioning as three clamps in one. Ready-to-use out of the box, the nVent CADDY EZ Riser features pre-drilled threaded rod holes for standoff installations and score marks for simple ear removal in spaces where full-sized riser clamps do not fit.

Contractors can enjoy simplified material handling with a multi-functional clamp that allows for various orientations and retains listing even when ears are removed.

## CERTIFICERINGER

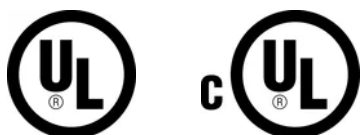

## FUNKTIONER

Only one tool needed to tighten due to serrated wash-heads

Installs up to 60% faster than standard riser clamps

Integrated second set of bolt holes allow the assembly to adapt from a riser clamp into a stand-off support easily

No need to stock and use separate part families for standard and close-quarter clamps to offer a full range of listed parts

Conforms with Federal Specification WW-H-171 (Type 8), Manufacturers Standardization Society (MSS) SP-58 (Type 8)

## SPECIFIKATIONER

**Finish:** Electrogalvanized

**Materiale:** Stål

Table 1/2

| Katalognummer | Artikelnummer | Outer Diameter (OD) | Hole Size (HS) | A        | B        | C       |
|---------------|---------------|---------------------|----------------|----------|----------|---------|
| EZR0050       | 179225        | 21.3 mm             | 9.9 mm         | 215.9 mm | 130.2 mm | 22.2 mm |

| Katalognummer | Artikelnummer | Outer Diameter (OD) | Hole Size (HS) | A        | B        | C       |
|---------------|---------------|---------------------|----------------|----------|----------|---------|
| EZR0075       | 179226        | 26.7 mm             | 9.9 mm         | 228.6 mm | 136.5 mm | 22.2 mm |
| EZR0100       | 179227        | 33.4 mm             | 9.9 mm         | 228.6 mm | 142.9 mm | 22.2 mm |
| EZR0125       | 179228        | 42.2 mm             | 9.9 mm         | 241.3 mm | 152.4 mm | 22.2 mm |
| EZR0150       | 179229        | 48.3 mm             | 9.9 mm         | 250.8 mm | 158.8 mm | 22.2 mm |
| EZR0200       | 179230        | 60.3 mm             | 9.9 mm         | 260.4 mm | 177.8 mm | 25.4 mm |
| EZR0250       | 179231        | 73 mm               | 9.9 mm         | 279.4 mm | 190.5 mm | 25.4 mm |
| EZR0300       | 179232        | 88.9 mm             | 9.9 mm         | 298.5 mm | 206.4 mm | 25.4 mm |
| EZR0350       | 179233        | 101.6 mm            | 13.2 mm        | 320.7 mm | 238.1 mm | 31.8 mm |
| EZR0400       | 179234        | 114.3 mm            | 13.2 mm        | 330.2 mm | 254 mm   | 31.8 mm |
| EZR0500       | 179235        | 141.3 mm            | 13.2 mm        | 368.3 mm | 298.5 mm | 38.1 mm |
| EZR0600       | 179236        | 168.3 mm            | 13.2 mm        | 406.4 mm | 323.9 mm | 38.1 mm |

| Table 2/2     |               |             |
|---------------|---------------|-------------|
| Katalognummer | Artikelnummer | Static Load |
| EZR0050       | 179225        | 1100N       |
| EZR0075       | 179226        | 1100N       |
| EZR0100       | 179227        | 1100N       |
| EZR0125       | 179228        | 1100N       |
| EZR0150       | 179229        | 1100N       |
| EZR0200       | 179230        | 1100N       |

 
| Katalognummer | Artikelnummer | Static Load |
|---------------|---------------|-------------|
| EZR0250       | 179231        | 1735N       |
| EZR0300       | 179232        | 2400N       |
| EZR0350       | 179233        | 2980N       |
| EZR0400       | 179234        | 3600N       |
| EZR0500       | 179235        | 5200N       |
| EZR0600       | 179236        | 6900N       |

## YDERLIGERE PRODUKTOPLYSNINGER

Clamp is fitted for steel pipe and should be installed below a coupling or shear lug, with bolts torqued to recommended value.

Use of a socket or driver is recommended for installation.

## DIAGRAMS



## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

