

nVent CADDY Macrofix Insulated M8



CERTIFICERINGER



FUNKTIONER

Return-lip on the hanger prevents the rubber from detaching, eliminating rework during installation

Plastic washer prevents screws from falling out during installation

Combo head bolt works with slotted, hex, or Phillips drivers

Longer ears position the screw farther from the hanger, improving tool clearance when the screw is tightened

Screw length has been optimized to accommodate an increased pipe range, reducing inventory

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

SPECIFIKATIONER

Finish: Electrogalvanized

Temperature: -50 to 110 °C

Table 1/2

Katalognummer	Artikelnummer	Materiale	Outer Diameter (OD)	NB/DN	Rod Size (RS)	Width (W)
---------------	---------------	-----------	---------------------	-------	---------------	-----------

MFE015	586201	EPDM-SBR Rubber, Stål	11 - 15 mm	8	M8	20 mm
MFE019	586202	EPDM-SBR Rubber, Stål	15 - 19 mm	10	M8	20 mm
MFE025	586203	EPDM-SBR Rubber, Stål	19 - 25 mm	15	M8	20 mm
MFE031	586204	EPDM-SBR Rubber, Stål	25 - 31 mm	20	M8	20 mm
MFE037	586205	EPDM-SBR Rubber, Stål	31 - 37 mm	25	M8	20 mm
MFE044	586206	EPDM-SBR Rubber, Stål	37 - 44 mm	32	M8	20 mm
MFE050	586207	EPDM-SBR Rubber, Stål	44 - 50 mm	40	M8	20 mm
MFE058	586208	EPDM-SBR Rubber, Stål	50 - 58 mm		M8	20 mm
MFE068	586209	EPDM-SBR Rubber, Stål	58 - 68 mm	50	M8	20 mm

Table 2/2


Katalognummer	Artikelnummer	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)	Static Load
MFE015	586201	1 mm	6	17mm	1000N
MFE019	586202	1 mm	6	17mm	1000N
MFE025	586203	1 mm	6	22mm	1000N
MFE031	586204	1 mm	6	22mm	1000N
MFE037	586205	1 mm	6	22mm	1000N
MFE044	586206	1 mm	6	27mm	1000N
MFE050	586207	1.25 mm	6	27mm	1500N
MFE058	586208	1.25 mm	6	27mm	1500N

Katalognummer	Artikelnummer	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)	Static Load
MFE068	586209	1.25 mm	6	32mm	1500N

YDERLIGERE PRODUKTOPLYSNINGER

Lining is EPDM rubber.

DIAGRAMS

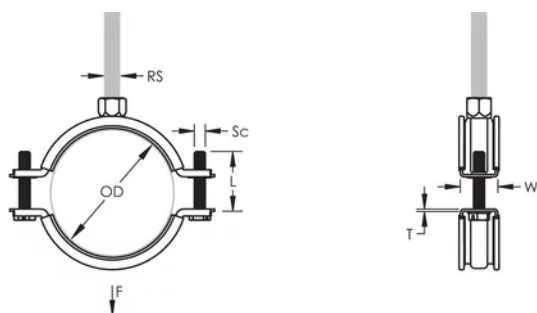

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

