

nVent CADDY Macrofix Plus Insulated



CERTIFICERINGER



FUNKTIONER

Increased opening angle easily accommodates all standard-sized pipes

Quick locking system prevents the hanger from accidentally opening when pipe is moved or adjusted

Quick locking system easily closes with one hand

Return-lip on the hanger prevents the rubber from detaching, eliminating rework during installation

Thread impression retains quick locking captive screw and prevents it from falling out during installation

Combo head bolt works with slotted, hex, or Phillips drivers

Longer ears position the screw farther from the hanger, improving tool clearance when the screw is tightened

Combination nut can be attached to M8 or M10 threaded rod, simplifying material handling

Screw length has been optimized to accommodate an increased pipe range, reducing inventory

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

SPECIFIKATIONER

Farve: Black

Finish: Electrogalvanized

Temperature: -50 to 110 °C

Table 1/2

Katalognummer	Artikelnummer	Materiale	Outer Diameter (OD)	Rod Size (RS)	NB/DN	Width (W)
MFP015	586701	Stål, EPDM-SBR Rubber	11 - 15 mm	M8, M10	8	20 mm
MFP019	586702	Stål, EPDM-SBR Rubber	15 - 19 mm	M8, M10	10	20 mm
MFP025	586703	Stål, EPDM-SBR Rubber	19 - 25 mm	M8, M10	15	20 mm
MFP031	586704	Stål, EPDM-SBR Rubber	25 - 31 mm	M8, M10	20	20 mm
MFP037	586705	Stål, EPDM-SBR Rubber	31 - 37 mm	M8, M10	25	20 mm
MFP044	586706	Stål, EPDM-SBR Rubber	37 - 44 mm	M8, M10	32	20 mm
MFP051	586707	Stål, EPDM-SBR Rubber	45 - 51 mm	M8, M10	40	21 mm
MFP058	586708	Stål, EPDM-SBR Rubber	50 - 58 mm	M8, M10		21 mm
MFP068	586709	Stål, EPDM-SBR Rubber	58 - 68 mm	M8, M10	50	21 mm
MFP078	586710	Stål, EPDM-SBR Rubber	68 - 78 mm	M8, M10	65	23 mm
MFP088	586711	Stål, EPDM-SBR Rubber	78 - 88 mm	M8, M10		23 mm
MFP098	586712	Stål, EPDM-SBR Rubber	88 - 98 mm	M8, M10	80	23 mm
MFP108	586713	Stål, EPDM-SBR Rubber	98 - 108 mm	M8, M10	90	23 mm
MFP118	586714	Stål, EPDM-SBR Rubber	108 - 118 mm	M8, M10	100	23 mm
MFP128	586715	Stål, EPDM-SBR Rubber	118 - 128 mm	M8, M10		23 mm
MFP138	586716	Stål, EPDM-SBR Rubber	128 - 138 mm	M8, M10		23 mm
MFP148	586717	Stål, EPDM-SBR Rubber	138 - 148 mm	M8, M10	125	25 mm

Katalognummer	Artikelnummer	Materiale	Outer Diameter (OD)	Rod Size (RS)	NB/DN	Width (W)
MFP160	586718	Stål, EPDM-SBR Rubber	150 - 160 mm	M8, M10		25 mm
MFP170	586719	Stål, EPDM-SBR Rubber	160 - 170 mm	M8, M10	150	25 mm
MFP200	586720	Stål, EPDM-SBR Rubber	190 - 200 mm	M8, M10		27 mm
MFP215	586721	Stål, EPDM-SBR Rubber	205 - 215 mm	M8, M10		27 mm

Table 2/2


Katalognummer	Artikelnummer	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)	Static Load
MFP015	586701	1 mm	6	27mm	1000N
MFP019	586702	1 mm	6	27mm	1000N
MFP025	586703	1 mm	6	32mm	1000N
MFP031	586704	1 mm	6	32mm	1000N
MFP037	586705	1 mm	6	32mm	1000N
MFP044	586706	1 mm	6	37mm	1000N
MFP051	586707	1.25 mm	6	37mm	1500N
MFP058	586708	1.25 mm	6	37mm	1500N
MFP068	586709	1.25 mm	6	40mm	1500N
MFP078	586710	1.5 mm	6	40mm	2000N
MFP088	586711	1.5 mm	6	40mm	2000N
MFP098	586712	1.75 mm	6	45mm	2500N

Katalognummer	Artikelnummer	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)	Static Load
MFP108	586713	1.75 mm	6	45mm	2500N
MFP118	586714	1.75 mm	6	50mm	2500N
MFP128	586715	2 mm	6	50mm	3000N
MFP138	586716	2 mm	6	50mm	3000N
MFP148	586717	2 mm	6	50mm	3200N
MFP160	586718	2 mm	6	50mm	3200N
MFP170	586719	2 mm	6	50mm	3200N
MFP200	586720	2.25 mm	6	50mm	3600N
MFP215	586721	2.25 mm	6	50mm	3600N

YDERLIGERE PRODUKTOPLYSNINGER

Lining is EPDM rubber.

DIAGRAMS

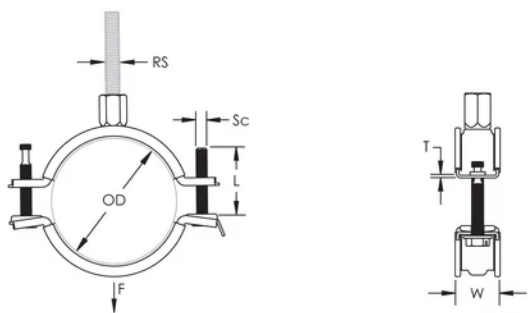

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

