

nVent CADDY Pyramid Equipment Support Post Base



FUNKTIONER

Ideal for use with strut channel type A and U-shaped brackets to create custom equipment supports

Height adjustable

Foam bottom offers low abrasion interface for better roof membrane protection

Compatible with roof surfaces including single ply, bituminous, metal and spray foam

Provides superior load distribution, even with varying rooftop surfaces

Hot-dip galvanized and UV stabilized for long lasting performance

SPECIFIKATIONER

Table 1/3

Katalognummer	Artikelnummer	Materiale	Finish	Temperature	Static Load Safety Factor	Height (H)
PEB	360425	Stål, Polypropylene, Polyethylene	Hot-Dip Galvanized	-34 to 54.4 °C	3:1	305 - 457 mm

Table 2/3


Katalognummer	Artikelnummer	Length (L)	Width (W)	A	Surface Area	Unit Weight
PEB	360425	314mm	314 mm	76 mm	0.09m ²	4 kg

Katalognummer	Artikelnummer	Static Load
PEB	360425	3340N

YDERLIGERE PRODUKTOPLYSNINGER

The end user must select and evaluate the strut framing to ensure the custom assembled equipment support can properly support the applied load.

DIAGRAMS

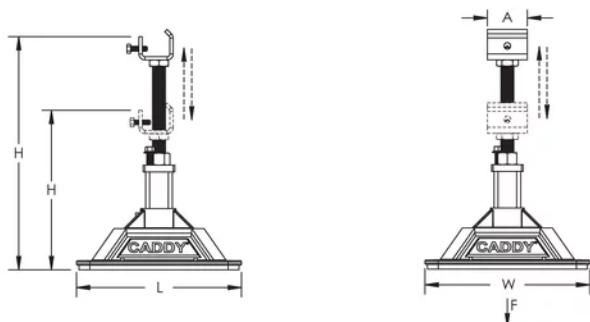

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

