

nVent CADDY Pyramid H-Frame Post Base



FUNKTIONER

Foam or rubber bottom offers low abrasion interface for better roof membrane protection

Compatible with roof surfaces including single ply, bituminous, metal and spray foam

Provides superior load distribution, even with varying rooftop surfaces

Rubber rooftop interface ideal for solar panel array installations

Mounting hardware pre-installed in bases

Hot-dip galvanized and UV stabilized for long lasting performance

Accepts standard strut channels

SPECIFIKATIONER

Table 1/3

Katalognummer	Artikelnummer	Materiale	Finish	Temperature	Static Load Safety Factor	Rooftop Interface
PHB	360422	Stål, Polypropylene, Polyethylene	Hot-Dip Galvanized	-34 to 54.4 °C	3:1	Foam


Table 2/3

Katalognummer	Artikelnummer	Strut Type	Height (H)	Length (L)	Width (W)	Surface Area
PHB	360422	A (41 x 41 mm)	117 mm	314mm	314 mm	0.09m ²

Table 3/3

Katalognummer	Artikelnummer	Unit Weight	Static Load
PHB	360422	1.8 kg	3335N

DIAGRAMS

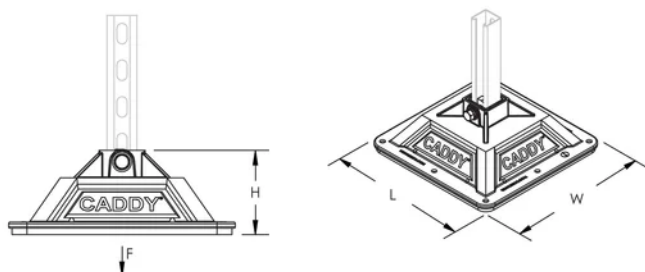

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

