

nVent CADDY Self-Cutting Cable Tie



The nVent CADDY Self-Cutting Cable Tie is a versatile, tool-free datacom solution for bundling large amounts of cables. This simple, yet innovative product features a built-in cutting blade to ensure a secure fastening and a safe, clean tie-off finish. Made from durable 6/6 nylon, the Self-Cutting Cable Tie boasts a robust 50lb/ 22Kg of tensile strength.

CERTIFICERINGER



FUNKTIONER

Eliminates sharp edges and protects exposed skin from cuts during installation

Lock and twist to cut, no cutting tools required

Different colors including a black UV-protected version to meet specific needs

RoHS (Restriction of Hazardous Substances Directive) compliant

Halogen free

cULus Listed to UL 62275/CSA C22.2 No. 62275, UL Certified to IEC 62275

SPECIFIKATIONER

Complies With: IEC® 60695-2-11 (Glow Wire Test 960 °C)

Table 1/2



Katalognummer	Artikelnummer	Materiale	Farve	Length (L)	Width (W)	Installation Temperature
CADTIESC8CNA P	601019	Nylon, Stainless Steel 301 (EN 1.4310)	Natural	203.2mm	4.32 mm	0 °C Min
CADTIESC11CN AP	601001	Nylon, Stainless Steel 301 (EN 1.4310)	Natural	279.4mm	4.32 mm	0 °C Min

Katalognummer	Artikelnummer	Materiale	Farve	Length (L)	Width (W)	Installation Temperature
CADTIESC14CBAP	601009	Nylon, Stainless Steel 301 (EN 1.4310)	Black	355.6mm	4.32 mm	0 °C Min
CADTIESC14CNAP	601010	Nylon, Stainless Steel 301 (EN 1.4310)	Natural	355.6mm	4.32 mm	0 °C Min
CADTIESC11CBAP	601000	Nylon, Stainless Steel 301 (EN 1.4310)	Black	279.4mm	4.32 mm	0 °C Min
CADTIESC8CBAP	601018	Nylon, Stainless Steel 301 (EN 1.4310)	Black	203.2mm	4.32 mm	0 °C Min

Table 2/2

Katalognummer	Artikelnummer	Driftstemperatur
CADTIESC8CNAP	601019	-20 to 85 °C
CADTIESC11CNAP	601001	-20 to 85 °C
CADTIESC14CBAP	601009	-20 to 85 °C
CADTIESC14CNAP	601010	-20 to 85 °C
CADTIESC11CBAP	601000	-20 to 85 °C
CADTIESC8CBAP	601018	-20 to 85 °C

 DIAGRAMS

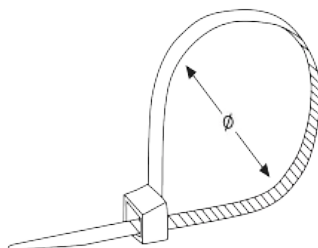

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

