

# nVent CADDY Speed Link Catenary Cable Spool



## FUNKTIONER

Used for installing custom lengths of catenary cable with two locking devices

Spool with nVent CADDY Speed Link steel wire

Wire rope constructed from 7 bundles of 19 strands each of steel aircraft wire

## SPECIFIKATIONER

**Finish:** Hot-Dip Galvanized

**Materiale:** Stål

Table 1/1

Katalognummer	Artikelnummer	Wire Rope Diameter	Wire Rope Length	Angle (a)
SLC6CTO	196819	6 mm		60 ° Max
SLC6L50	196821	6 mm	50m	60 ° Max

## YDERLIGERE PRODUKTOPLYSNINGER


Static load 1 represents a point load in the center of the catenary installation. Static load 2 represents a two or three point distributed load on the catenary installation. Static load 3 represents a four or more point distributed load on the catenary installation.

Preload of the wire rope must be applied using Catenary Tensioning Tool.

Cut-to-order (CTO) lengths orderable in meter increments.

Horizontal Installation		
Preload	1000 N	450 N
Static Load 1 (F1)	490 N	590 N
Static Load 2 (F2)	880 N	1080 N
Static Load 3 (F3)	980 N	1180 N
Vertical Installation		
Static Load 4 (F4)	4440 N	

## DIAGRAMS

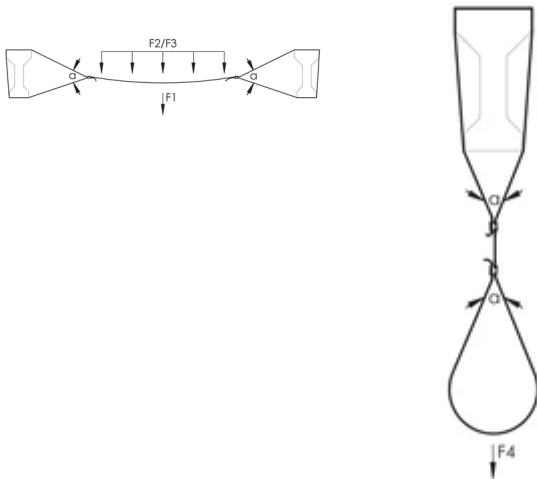

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden unkladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

