

nVent CADDY Speed Link LD with Hook



CERTIFICERINGER



FUNKTIONER

Complete system includes wire, locking device and pre-assembled hook end fitting

Hooks to a wide range of nVent CADDY fasteners

Fastens to the building structure or hanging services by looping around and hooking to wire rope

Easy to remove for applications requiring maintenance

Spring latch helps provide secure connection

Insert cable through hole and use bottom side of hook as an end stop

SPECIFIKATIONER

Wire Rope Diameter:	1.5 mm
Static Load Safety Factor:	5:1
Materiale:	Stainless Steel 304 (EN 1.4301)

Table 1/1

Katalognummer	Artikelnummer	Wire Rope Length	A	B	C	Static Load
SLD15L2S	195935	2m	58.4 mm	22.9 mm	6.4 mm	195N

Katalognummer	Artikelnummer	Wire Rope Length	A	B	C	Static Load
SLD15L5S	195940	5m	58.4 mm	22.9 mm	6.4 mm	195N
SLD15L10S	195945	10m	58.4 mm	22.9 mm	6.4 mm	195N


Width (W): 12.7 mm

Height (H): 19 mm

YDERLIGERE PRODUKTOPLYSNINGER

Wire and pre-assembled hook end fitting made of Stainless Steel 316 (1.4401).

DIAGRAMS

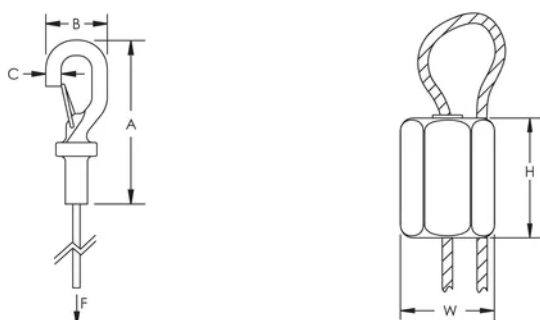

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

