

nVent CADDY Speed Link SLDM with Toggle



FUNKTIONER

Complete system includes wire, locking device and pre-assembled toggle end fitting

Attaches to clearance holes in a variety of structures or hanging devices

Ideal for supporting lighting fixtures

Sleek, low-profile locking device reduces visual impact

Keyless locking device is adjustable even after installation

SPECIFIKATIONER

Table 1/2


 

Katalognummer	Artikelnummer	Materiale	Finish	Wire Rope Diameter	Wire Rope Length	A
SLDM615L2T	196044	Stål	Electrogalvanized	1.5 mm	2m	39 mm

Table 2/2

Katalognummer	Artikelnummer	B	Static Load
SLDM615L2T	196044	5 mm	195N

Rod Size (RS): 6
Length (L): 7mm
Width (W): 9.2 mm
Height (H): 24.5 mm

DIAGRAMS

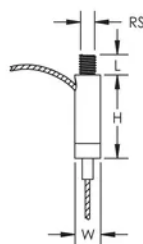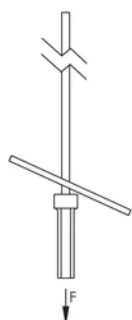

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

