

nVent CADDY Speed Link SLK with Angle Bracket



CERTIFICERINGER



FUNKTIONER

Complete system includes wire, locking device and pre-assembled angle bracket end fitting

Ideal for attaching to concrete, steel or wood surfaces

Simple alternative to jack chain and additional hardware

SPECIFIKATIONER

Static Load Safety Factor: 5:1

Finish: Electrogalvanized

Complies With: SMACNA HVAC-DCS

Table 1/3

Katalognummer	Artikelnummer	Materiale	Wire Rope Diameter	Wire Rope Length	A	Hole Size (HS)
SLK15L1AB	196500	Steel, Zinc Alloy, Polypropylene	1.5 mm	1m	22.6 mm	7.1 mm

Katalognummer	Artikelnummer	Materiale	Wire Rope Diameter	Wire Rope Length	A	Hole Size (HS)
SLK15L2AB	196501	Steel, Zinc Alloy, Polypropylene	1.5 mm	2m	22.6 mm	7.1 mm
SLK15L3AB	196502	Steel, Zinc Alloy, Polypropylene	1.5 mm	3m	22.6 mm	7.1 mm
SLK15L5AB	196503	Steel, Zinc Alloy, Polypropylene	1.5 mm	5m	22.6 mm	7.1 mm
SLK2L2AB	196529	Steel, Zinc Alloy, Polypropylene	2 mm	2m	22.6 mm	7.1 mm
SLK2L3AB	196530	Steel, Zinc Alloy, Polypropylene	2 mm	3m	22.6 mm	7.1 mm
SLK2L5AB	196531	Steel, Zinc Alloy, Polypropylene	2 mm	5m	22.6 mm	7.1 mm
SLK3L10AB	196716	Steel, Zinc Alloy, Polypropylene	3 mm	10m	22.6 mm	7.1 mm
SLK3L2AB	196713	Steel, Zinc Alloy, Polypropylene	3 mm	2m	22.6 mm	7.1 mm
SLK3L5AB	196715	Steel, Zinc Alloy, Polypropylene	3 mm	5m	22.6 mm	7.1 mm

Table 2/3


Katalognummer	Artikelnummer	Height (H)	Width (W)	Thickness (T)	Angle (a)	Static Load
SLK15L1AB	196500	55 mm	19 mm	12.5 mm	90 ° Max	195N
SLK15L2AB	196501	55 mm	19 mm	12.5 mm	90 ° Max	195N
SLK15L3AB	196502	55 mm	19 mm	12.5 mm	90 ° Max	195N
SLK15L5AB	196503	55 mm	19 mm	12.5 mm	90 ° Max	195N
SLK2L2AB	196529	55 mm	19 mm	12.5 mm	90 ° Max	440N

Katalognummer	Artikelnummer	Height (H)	Width (W)	Thickness (T)	Angle (a)	Static Load
SLK2L3AB	196530	55 mm	19 mm	12.5 mm	90 ° Max	440N
SLK2L5AB	196531	55 mm	19 mm	12.5 mm	90 ° Max	440N
SLK3L10AB	196716	62 mm	24 mm	16 mm	90 ° Max	890N
SLK3L2AB	196713	62 mm	24 mm	16 mm	90 ° Max	890N
SLK3L5AB	196715	62 mm	24 mm	16 mm	90 ° Max	890N

Table 3/3

Katalognummer	Artikelnummer	Certificeringer
SLK15L1AB	196500	ITB, UL, cUL
SLK15L2AB	196501	ITB, UL, cUL
SLK15L3AB	196502	cUL, ITB, UL
SLK15L5AB	196503	ITB, UL, cUL
SLK2L2AB	196529	ITB, UL, cUL
SLK2L3AB	196530	ITB, UL, cUL
SLK2L5AB	196531	ITB, UL, cUL
SLK3L10AB	196716	
SLK3L2AB	196713	
SLK3L5AB	196715	

DIAGRAMS

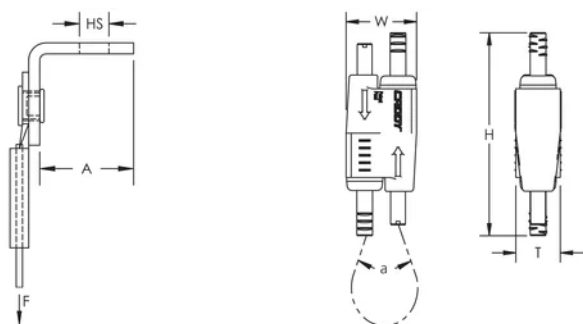

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

