

nVent CADDY Speed Link SLK with Drop Wire Clip



FUNKTIONER

Complete system includes wire, locking device and pre-assembled drop wire clip end fitting for catenary cable

Can be used to hang services from catenary cable or act as an intermediate support to reduce sag and tension

Easily snaps onto catenary cable and locks in place when closed

Tool-free clip can be hand-closed on the catenary wire

SPECIFIKATIONER

Static Load Safety Factor: 5:1

Finish: Electrogalvanized;nVent CADDY Armour

Table 1/3

Katalognummer	Artikelnummer	Materiale	Wire Rope Diameter	Wire Rope Length	A	B
SLK15L1DW6	196830	Steel, Spring Steel, Polypropylene, Zinc Alloy	1.5 mm	1m	70 mm	20 mm
SLK15L2DW6	196831	Steel, Spring Steel, Polypropylene, Zinc Alloy	1.5 mm	2m	70 mm	20 mm

Katalognummer	Artikelnummer	Materiale	Wire Rope Diameter	Wire Rope Length	A	B
SLK15L3DW6	196832	Steel, Spring Steel, Polypropylene, Zinc Alloy	1.5 mm	3m	70 mm	20 mm
SLK15L5DW6	196833	Steel, Spring Steel, Polypropylene, Zinc Alloy	1.5 mm	5m	70 mm	20 mm
SLK2L1DW6	196836	Steel, Spring Steel, Polypropylene, Zinc Alloy	2 mm	1m	70 mm	20 mm
SLK2L2DW6	196837	Steel, Spring Steel, Polypropylene, Zinc Alloy	2 mm	2m	70 mm	20 mm
SLK2L3DW6	196838	Steel, Spring Steel, Polypropylene, Zinc Alloy	2 mm	3m	70 mm	20 mm
SLK2L5DW6	196839	Steel, Spring Steel, Polypropylene, Zinc Alloy	2 mm	5m	70 mm	20 mm
SLK3L1DW6	196842	Steel, Spring Steel, Polypropylene, Zinc Alloy	3 mm	1m	70 mm	20 mm
SLK3L2DW6	196843	Steel, Spring Steel, Polypropylene, Zinc Alloy	3 mm	2m	70 mm	20 mm
SLK3L3DW6	196844	Steel, Spring Steel, Polypropylene, Zinc Alloy	3 mm	3m	70 mm	20 mm
SLK3L5DW6	196845	Steel, Spring Steel, Polypropylene, Zinc Alloy	3 mm	5m	70 mm	20 mm

Table 2/3

Katalognummer	Artikelnummer	C	Diameter (Ø)	Height (H)	Width (W)
SLK15L1DW6	196830	25 mm	6 mm	55 mm	19 mm


Katalognummer	Artikelnummer	C	Diameter (Ø)	Height (H)	Width (W)
SLK15L2DW6	196831	25 mm	6 mm	55 mm	19 mm
SLK15L3DW6	196832	25 mm	6 mm	55 mm	19 mm
SLK15L5DW6	196833	25 mm	6 mm	55 mm	19 mm
SLK2L1DW6	196836	25 mm	6 mm	55 mm	19 mm
SLK2L2DW6	196837	25 mm	6 mm	55 mm	19 mm
SLK2L3DW6	196838	25 mm	6 mm	55 mm	19 mm
SLK2L5DW6	196839	25 mm	6 mm	55 mm	19 mm
SLK3L1DW6	196842	25 mm	6 mm	62 mm	24 mm
SLK3L2DW6	196843	25 mm	6 mm	62 mm	24 mm
SLK3L3DW6	196844	25 mm	6 mm	62 mm	24 mm
SLK3L5DW6	196845	25 mm	6 mm	62 mm	24 mm

Table 3/3

Katalognummer	Artikelnummer	Thickness (T)	Angle (a)	Static Load
SLK15L1DW6	196830	12.5 mm	90 ° Max	195N
SLK15L2DW6	196831	12.5 mm	90 ° Max	195N
SLK15L3DW6	196832	12.5 mm	90 ° Max	195N
SLK15L5DW6	196833	12.5 mm	90 ° Max	195N
SLK2L1DW6	196836	12.5 mm	90 ° Max	440N
SLK2L2DW6	196837	12.5 mm	90 ° Max	440N

Katalognummer	Artikelnummer	Thickness (T)	Angle (a)	Static Load
SLK2L3DW6	196838	12.5 mm	90 ° Max	440N
SLK2L5DW6	196839	12.5 mm	90 ° Max	440N
SLK3L1DW6	196842	16 mm	90 ° Max	700N
SLK3L2DW6	196843	16 mm	90 ° Max	700N
SLK3L3DW6	196844	16 mm	90 ° Max	700N
SLK3L5DW6	196845	16 mm	90 ° Max	700N

DIAGRAMS

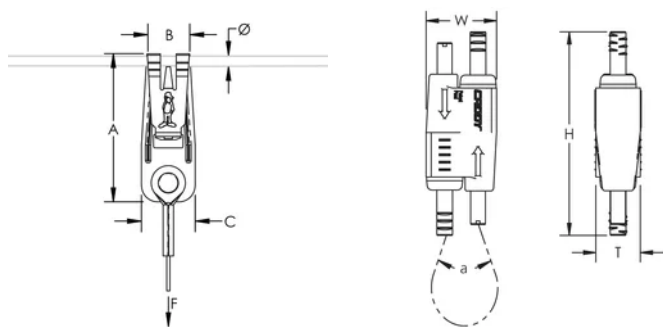

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

