

nVent CADDY Speed Link SLK with Hammer-On Flange Clip



CERTIFICERINGER



FUNKTIONER

Complete system includes wire, locking device and pre-assembled nVent CADDY Hammer-On Flange Clip end fitting

Installs with just a hammer

Fits most beams

SPECIFIKATIONER

Static Load Safety Factor: 5:1
Finish: Electrogalvanized
Complies With: SMACNA HVAC-DCS

Table 1/1

Katalognummer	Artikelnummer	Materiale	Wire Rope Diameter	Wire Rope Length	Flange Thickness (FT)	Static Load
SLK2L34H24	196535	Steel, Polypropylene, Zinc Alloy	2 mm	3m	3 - 8 mm	440N

Katalognummer	Artikelnummer	Materiale	Wire Rope Diameter	Wire Rope Length	Flange Thickness (FT)	Static Load
SLK15L34H24	196506	Steel, Polypropylene, Zinc Alloy	1.5 mm	3m	3 - 8 mm	195N
SLK15L34H58	196507	Steel, Polypropylene, Zinc Alloy	1.5 mm	3m	8 - 14 mm	195N
SLK2L34H58	196536	Steel, Polypropylene, Zinc Alloy	2 mm	3m	8 - 14 mm	440N


Thickness (T): 12.5 mm

Width (W): 19 mm

Height (H): 55 mm

Angle (a): 90 ° Max

DIAGRAMS

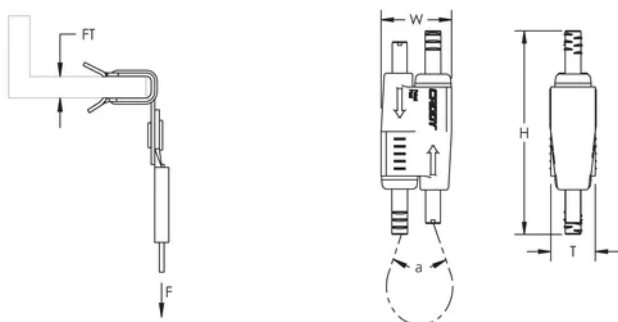

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRachte

