

nVent CADDY Speed Link SLK Locking Device



CERTIFICERINGER



FUNKTIONER

Push/pull keyless release allows easy adjustments

Low-profile locking device minimizes visual impact

Cable spread of 90 degrees allows positioning the device closer to the load

Keyless release tubes are easy to operate while wearing gloves

Double-sided locking mechanism enables simple height adjustment

SPECIFIKATIONER

Materiale: Stål; Polypropylene; Zinc Alloy

Table 1/2

Katalognummer	Artikelnummer	Wire Rope Diameter	Height (H)	Width (W)	Thickness (T)	Angle (a)
SLK2R10	196770	1.5 - 2 mm	55 mm	19 mm	12.5 mm	90 ° Max
SLK2C200	196600	1.5 - 2 mm	55 mm	19 mm	12.5 mm	90 ° Max

Katalognummer	Artikelnummer	Wire Rope Diameter	Height (H)	Width (W)	Thickness (T)	Angle (a)
SLK3C200	196730	3 mm	62 mm	24 mm	16 mm	90 ° Max


Table 2/2

Katalognummer	Artikelnummer	Certificeringer
SLK2R10	196770	UL, cUL, ITB
SLK2C200	196600	ITB, UL, cUL
SLK3C200	196730	

YDERLIGERE PRODUKTOPLYSNINGER

Locking devices are only to be used with nVent CADDY Speed Link wire spools and accessories with the same specified Wire Rope Diameter as the locking device. Do not use with any other wires.

DIAGRAMS

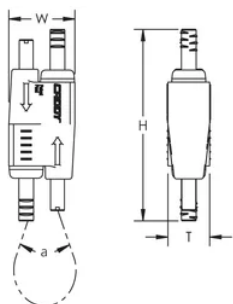

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

