

nVent CADDY Speed Link SLK with Toggle



CERTIFICERINGER



FUNKTIONER

Complete system includes wire, locking device and pre-assembled toggle end fitting

Attaches to clearance holes in a variety of structures or hanging devices

Ideal for supporting lighting fixtures

Also available in Y-toggle configuration

SPECIFIKATIONER

Wire Rope Diameter:	1.5 mm
Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Complies With:	SMACNA HVAC-DCS

Table 1/1

Katalognummer	Artikelnummer	Materiale	Wire Rope Length	A	B	Static Load
SLK15L10T	196526	Steel, Zinc Alloy, Polypropylene	10m	39 mm	5 mm	195N

Katalognummer	Artikelnummer	Materiale	Wire Rope Length	A	B	Static Load
SLK15L1T	196521	Steel, Zinc Alloy, Polypropylene	1m	39 mm	5 mm	195N
SLK15L2T	196522	Steel, Zinc Alloy, Polypropylene	2m	39 mm	5 mm	195N
SLK15L2TR2	196644	Steel, Zinc Alloy, Polypropylene	2m	39 mm	5 mm	195N
SLK15L3T	196523	Steel, Zinc Alloy, Polypropylene	3m	39 mm	5 mm	195N
SLK15L5T	196524	Steel, Zinc Alloy, Polypropylene	5m	39 mm	5 mm	195N
SLK15L7T	196525	Steel, Zinc Alloy, Polypropylene	7m	39 mm	5 mm	195N


Thickness (T): 12.5 mm

Width (W): 19 mm

Height (H): 55 mm

Angle (a): 90 ° Max

DIAGRAMS

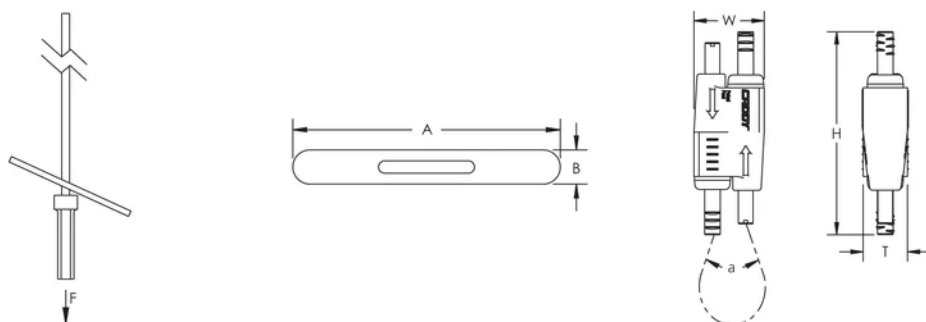

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRachte

