

nVent CADDY Speed Link SLK with Wedge Anchor



FUNKTIONER

Complete system includes wire, locking device and wedge anchor from fischerwerke GmbH &Co. KG

Quickly and easily attaches into cracked and non-cracked concrete

No special tools required

ETA 06/0175 approval available from fischerwerke GmbH &Co. KG

SPECIFIKATIONER

Static Load Safety Factor:	5:1
Drill Bit Diameter:	6mm
Drill Hole Depth:	31mm
Finish:	Electrogalvanized
Embedment Depth:	25 mm Min

Table 1/2


Katalognummer	Artikelnummer	Materiale	Wire Rope Diameter	Wire Rope Length	Length (L)	Height (H)
SLK2L3WA6	196735	Steel, Polypropylene, Zinc Alloy	2 mm	3m	54mm	55 mm
SLK15L2WA6	196671	Steel, Polypropylene, Zinc Alloy	1.5 mm	2m	54mm	55 mm

Katalognummer	Artikelnummer	Materiale	Wire Rope Diameter	Wire Rope Length	Length (L)	Height (H)
SLK2L2WA6	196734	Steel, Polypropylene, Zinc Alloy	2 mm	2m	54mm	55 mm
SLK15L3WA6	196672	Steel, Polypropylene, Zinc Alloy	1.5 mm	3m	54mm	55 mm

Table 2/2

Katalognummer	Artikelnummer	Width (W)	Thickness (T)	Angle (a)	Static Load
SLK2L3WA6	196735	19 mm	12.5 mm	90 ° Max	300N
SLK15L2WA6	196671	19 mm	12.5 mm	90 ° Max	195N
SLK2L2WA6	196734	19 mm	12.5 mm	90 ° Max	300N
SLK15L3WA6	196672	19 mm	12.5 mm	90 ° Max	195N

DIAGRAMS

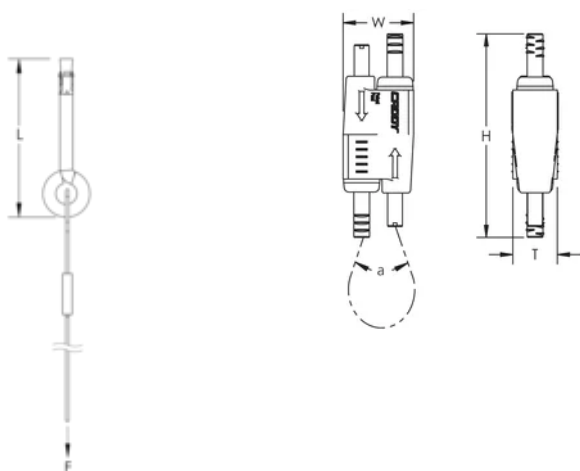

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRachte

