

nVent CADDY Speed Link SLK with Y-Toggle



CERTIFICERINGER



FUNKTIONER

Complete system includes wire, locking device and two pre-assembled toggle end fittings

Attaches to clearance holes in a variety of structures or hanging devices

Ideal for supporting lighting fixtures

SPECIFIKATIONER

Wire Rope Diameter:	1.5 mm
Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Materiale:	Stål; Zinc Alloy; Polypropylene
Complies With:	SMACNA HVAC-DCS

Table 1/1

Katalognummer	Artikelnummer	Wire Rope Length	Wire Rope "Y" Length (YL)	A	B	Static Load
SLK15Y300L3R2	196648	3m	0.3m	39 mm	5 mm	195N

Katalognummer	Artikelnummer	Wire Rope Length	Wire Rope "Y" Length (YL)	A	B	Static Load
SLK15Y500L3	196528	3m	0.5m	39 mm	5 mm	195N


Thickness (T): 12.5 mm

Width (W): 19 mm

Height (H): 55 mm

Angle (a): 90 ° Max

DIAGRAMS

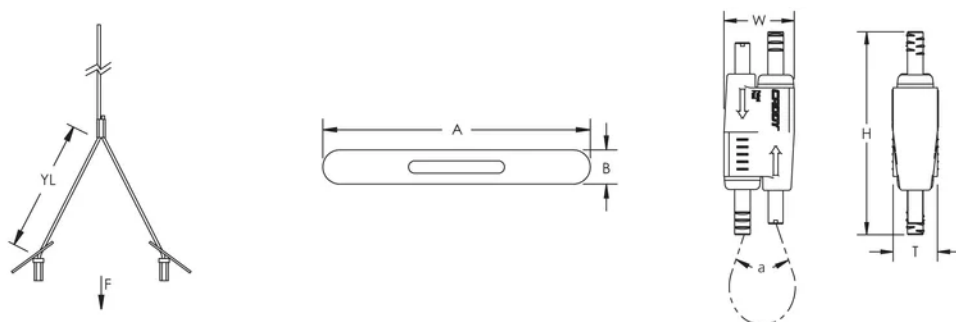

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

