


nVent CADDY Speed Link SLS with Decking Hook



CERTIFICERINGER

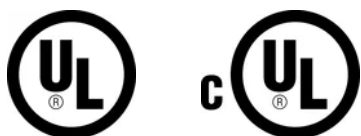

FUNKTIONER

Complete system includes wire, locking device and pre-assembled decking hook end fitting

Quickly and easily attaches to hollow metal decking

Spring-loaded ends snap into decking hole and lock into place

Innovative design helps protect the wire from sharp edges of decking hole, minimizing risk of damage to wire

Finger tightening of nut secures the locking device into position without tools

Installs in strut profiles without the need to insert fingers or tools into the strut

SPECIFIKATIONER

Wire Rope Diameter:	2 mm
Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Complies With:	SMACNA HVAC-DCS

Table 1/2

Katalognummer	Artikelnummer	Materiale	Wire Rope Length	Roof Decking Sheet Thickness	A	Hole Size 1 (HS1)
SLS2L3DH	196753	Steel, Zinc Alloy, Polypropylene	3m	1.5 mm Max	9.2 mm	8 mm
SLS2L5DH	196754	Steel, Zinc Alloy, Polypropylene	5m	1.5 mm Max	9.2 mm	8 mm

Table 2/2

Katalognummer	Artikelnummer	Static Load
SLS2L3DH	196753	270N
SLS2L5DH	196754	270N

Slot Size (SS): 8 x 6.5 mm - 8 x 10 mm

Hole Size 2 (HS2): 8 - 10 mm

Width (W): 16 mm

Height 2 (H2): 46.5mm

Height 1 (H1): 53mm

Thread Size (TS): M8

Thickness (T): 4 mm Max

YDERLIGERE PRODUKTOPLYSNINGER


The 2 mm locking device is compatible with C-Channel Types E0 and E0L.

Total load per wire on a multi-tier trapeze must not exceed static load.

Load rating is only applicable if the load-bearing capacity of the supporting element (steel decking) is adequate.

Check with deck manufacturer for recommended load capacity.

DIAGRAMS

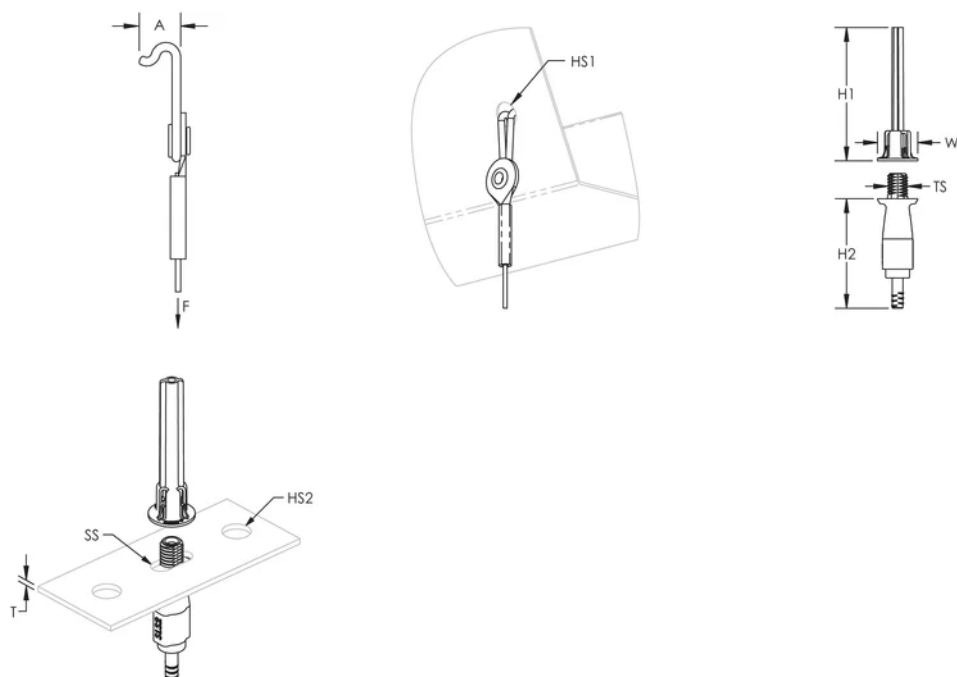

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

