

nVent CADDY Speed Link SLS with Hook



CERTIFICERINGER



FUNKTIONER

Complete system includes wire, locking device and pre-assembled hook end fitting

Hooks to a wide range of nVent CADDY fasteners

Fastens to the building structure or hanging services by looping around and hooking to wire rope

Easy to remove for applications requiring maintenance

Spring latch helps provide secure connection

Insert cable through hole and use bottom side of hook as an end stop

Finger tightening of nut secures the locking device into position without tools

Installs in strut profiles without the need to insert fingers or tools into the strut

SPECIFIKATIONER

Static Load Safety Factor: 5:1

Finish: Electrogalvanized

Complies With: SMACNA HVAC-DCS

Katalognummer	SLS2L10	SLS2L2	SLS2L3	SLS3L10	SLS3L2	SLS3L3	SLS3L5

Artikelnummer	196746	196742	196743	196752	196748	196749	196750
Materiale	Steel Zinc Alloy Polypropylene	Steel Zinc Alloy Polypropylene	Steel Zinc Alloy Polypropylene	Steel Zinc Alloy Polypropylene	Steel Zinc Alloy Polypropylene	Steel Zinc Alloy Polypropylene	Steel Zinc Alloy Polypropylene
Wire Rope Diameter	2 mm	2 mm	2 mm	3 mm	3 mm	3 mm	3 mm
Wire Rope Length	10m	2m	3m	10m	2m	3m	5m
A	57 mm	57 mm	57 mm	57.6 mm	57.6 mm	57.6 mm	57.6 mm
B	20 mm	20 mm	20 mm	23.2 mm	23.2 mm	23.2 mm	23.2 mm
C	5.5 mm	5.5 mm	5.5 mm	6.1 mm	6.1 mm	6.1 mm	6.1 mm
Height 1 (H1)	53mm	53mm	53mm	53mm	53mm	53mm	53mm
Height 2 (H2)	43.5mm	43.5mm	43.5mm	46.5mm	46.5mm	46.5mm	46.5mm
Thread Size (TS)	M8	M8	M8	M12	M12	M12	M12
Width (W)	16 mm	16 mm	16 mm	20 mm	20 mm	20 mm	20 mm
Hole Size (HS)	8 - 10 mm	8 - 10 mm	8 - 10 mm	12 - 14 mm	12 - 14 mm	12 - 14 mm	12 - 14 mm
Slot Size (SS)	8 x 6.5 mm - 8 x 10 mm	8 x 6.5 mm - 8 x 10 mm	8 x 6.5 mm - 8 x 10 mm	12 x 10 mm - 12 x 14 mm	12 x 10 mm - 12 x 14 mm	12 x 10 mm - 12 x 14 mm	12 x 10 mm - 12 x 14 mm
Thickness (T)	4 mm Max	4 mm Max	4 mm Max	6 mm Max	6 mm Max	6 mm Max	6 mm Max
Static Load	270N	270N	270N	670N	670N	670N	670N




YDERLIGERE PRODUKTOPLYSNINGER

The 2 mm locking device is compatible with C-Channel Types E0 and E0L.

The 3 mm locking device is compatible with C-Channel Types E1, E2, E2L, E3, E4, E5, Strut Channel Type C, Slotted, Strut Channel Type A, Slotted, Strut Channel Type AS, Perforated, Strut Channel Type CC, Slotted, Strut Channel Type AA, Slotted.

Total load per wire on a multi-tier trapeze must not exceed static load.

DIAGRAMS

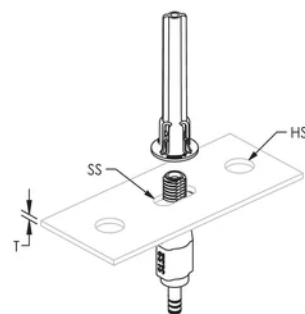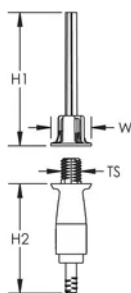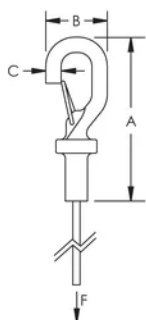

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

