

Oval Pipe Clamp with Nut



FUNKTIONER

Designed to support pre-insulated twin tubes and integrated power cable for solar heat collectors

Shape of clamp provides a stable attachment to wall or ceiling

SPECIFIKATIONER

Finish: Electrogalvanized

Materiale: Stål


Table 1/2

Katalognummer	Artikelnummer	NB/DN	Rod Size (RS)	A	B	Width (W)
MXOVDN25EG	403800	25	M8, M10	71 mm	124 mm	20 mm
MXOVDN1618EG	401245	16, 18	M8, M10	51 mm	88 mm	20 mm
MXOVDN1012EG	401161	10, 12	M8, M10	30 mm	69 mm	20 mm
MXOVDN20EG	401246	20	M8, M10	58 mm	108 mm	20 mm
MXOVDN1215EG	401244	12, 15	M8, M10	43 mm	78 mm	20 mm

Table 2/2

Katalognummer	Artikelnummer	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)
MXOVDN25EG	403800	2 mm	6	20mm
MXOVDN1618EG	401245	2 mm	6	20mm
MXOVDN1012EG	401161	2 mm	6	20mm
MXOVDN20EG	401246	2 mm	6	20mm
MXOVDN1215EG	401244	2 mm	6	20mm

DIAGRAMS

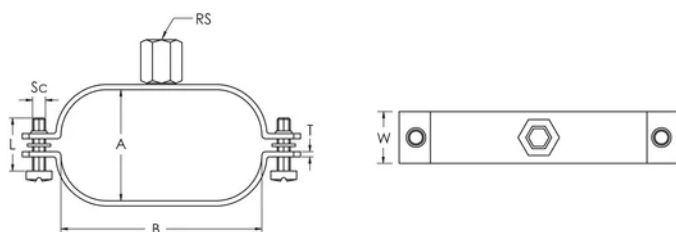

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRachte

