


PEMSA Wire Basket Tray Rapide

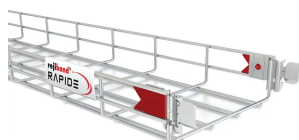

The PEMS A Wire Basket Tray is the backbone of PEMS A Wire Basket Tray System. Highly engineered features help ensure a secure installation that complies with industry codes and standards for high-performance cables. Clever design allows the installer to maximize field efficiency with the Rejiband Rapide Integrated Splice.

CERTIFICERINGER



FUNKTIONER

Provides optimal support for high-performance low voltage and data cables

Innovative Rejiband Rapide installation system

IEC 61537 load rating and earthing compliant

Responsive design and layout services, including seismic

SPECIFIKATIONER

Materiale: Carbon Steel

Finish: Electrogalvanized

Table 1/2

Katalognummer	Artikelnummer	Length (L)	Height (H)	Width (W)	A	Unit Weight
WBT100X100Q BG	823015	3000mm	100 mm	100 mm	32 mm	3.27 kg

Katalognummer	Artikelnummer	Length (L)	Height (H)	Width (W)	A	Unit Weight
WBT100X100Q EG	823014	3000mm	100 mm	100 mm	32 mm	3.27 kg
WBT100X150Q BG	823025	3000mm	100 mm	150 mm	32 mm	3.45 kg
WBT100X150Q EG	823024	3000mm	100 mm	150 mm	32 mm	3.45 kg
WBT100X200Q BG	823035	3000mm	100 mm	200 mm	32 mm	4.14 kg
WBT100X200Q EG	823034	3000mm	100 mm	200 mm	32 mm	4.14 kg
WBT100X300Q BG	823045	3000mm	100 mm	300 mm	32 mm	6.15 kg
WBT100X300Q EG	823044	3000mm	100 mm	300 mm	32 mm	6.15 kg
WBT100X400Q BG	823055	3000mm	100 mm	400 mm	32 mm	7.23 kg
WBT100X400Q EG	823054	3000mm	100 mm	400 mm	32 mm	7.23 kg
WBT100X450Q BG	823085	3000mm	100 mm	450 mm	32 mm	7.44 kg
WBT100X450Q EG	823084	3000mm	100 mm	450 mm	32 mm	7.44 kg
WBT100X500Q BG	823065	3000mm	100 mm	500 mm	32 mm	8.34 kg
WBT100X500Q EG	823064	3000mm	100 mm	500 mm	32 mm	8.34 kg

Katalognummer	Artikelnummer	Length (L)	Height (H)	Width (W)	A	Unit Weight
WBT100X600QBG	823075	3000mm	100 mm	600 mm	32 mm	9.42 kg
WBT100X600QEG	823074	3000mm	100 mm	600 mm	32 mm	9.42 kg
WBT60X100QBG	820015	3000mm	60 mm	100 mm	32 mm	2.43 kg
WBT60X100QEG	820014	3000mm	60 mm	100 mm	32 mm	2.43 kg
WBT60X150QBG	820025	3000mm	60 mm	150 mm	32 mm	2.6 kg
WBT60X150QEG	820024	3000mm	60 mm	150 mm	32 mm	2.6 kg
WBT60X200QBG	820035	3000mm	60 mm	200 mm	32 mm	3.33 kg
WBT60X200QEG	820034	3000mm	60 mm	200 mm	32 mm	3.33 kg
WBT60X300QBG	820045	3000mm	60 mm	300 mm	32 mm	5.13 kg
WBT60X300QEG	820044	3000mm	60 mm	300 mm	32 mm	5.13 kg
WBT60X400QBG	820055	3000mm	60 mm	400 mm	32 mm	6.21 kg
WBT60X400QEG	820054	3000mm	60 mm	400 mm	32 mm	6.21 kg
WBT60X450QBG	820085	3000mm	60 mm	450 mm	32 mm	6.39 kg

Katalognummer	Artikelnummer	Length (L)	Height (H)	Width (W)	A	Unit Weight
WBT60X450QEG	820084	3000mm	60 mm	450 mm	32 mm	6.39 kg
WBT60X500QBG	820065	3000mm	60 mm	500 mm	32 mm	7.35 kg
WBT60X500QEG	820064	3000mm	60 mm	500 mm	32 mm	7.35 kg
WBT60X600QBG	820079	3000mm	60 mm	600 mm	32 mm	8.43 kg
WBT60X600QEG	820078	3000mm	60 mm	600 mm	32 mm	8.43 kg
WBT60X60QBG	820005	3000mm	60 mm	60 mm	32 mm	2.32 kg


Table 2/2

Katalognummer	Artikelnummer	Farve
WBT100X100QBG	823015	Black
WBT100X100QEG	823014	Gray
WBT100X150QBG	823025	Black
WBT100X150QEG	823024	Gray
WBT100X200QBG	823035	Black
WBT100X200QEG	823034	Gray
WBT100X300QBG	823045	Black
WBT100X300QEG	823044	Gray
WBT100X400QBG	823055	Black

Katalognummer	Artikelnummer	Farve
WBT100X400QEG	823054	Gray
WBT100X450QBG	823085	Black
WBT100X450QEG	823084	Gray
WBT100X500QBG	823065	Black
WBT100X500QEG	823064	Gray
WBT100X600QBG	823075	Black
WBT100X600QEG	823074	Gray
WBT60X100QBG	820015	Black
WBT60X100QEG	820014	Gray
WBT60X150QBG	820025	Black
WBT60X150QEG	820024	Gray
WBT60X200QBG	820035	Black
WBT60X200QEG	820034	Gray
WBT60X300QBG	820045	Black
WBT60X300QEG	820044	Gray
WBT60X400QBG	820055	Black
WBT60X400QEG	820054	Gray
WBT60X450QBG	820085	Black

Katalognummer	Artikelnummer	Farve
WBT60X450QEG	820084	Gray
WBT60X500QBG	820065	Black
WBT60X500QEG	820064	Gray
WBT60X600QBG	820079	Black
WBT60X600QEG	820078	Gray
WBT60X60QBG	820005	Black

DIAGRAMS

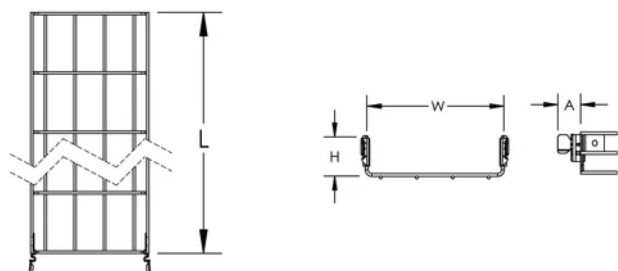

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

