

# Pipe/Cable Clamp



## FUNKTIONER

Captive threaded stud minimizes the need for additional hardware

With the UNICBAND Sign Support Bracket and Fixoband Strap, attachments to pipe and pole can be made

## SPECIFIKATIONER

Table 1/2

| Katalognummer | Artikelnummer | Materiale                       | Finish             | NB/DN | Outer Diameter (OD) | Width (W) |
|---------------|---------------|---------------------------------|--------------------|-------|---------------------|-----------|
| CR037HD       | 336300        | Stål                            | Hot-Dip Galvanized | 10    | 16 - 20 mm          | 16 mm     |
| CR037S4       | 336400        | Stainless Steel 304 (EN 1.4301) |                    | 10    | 16 - 20 mm          | 16 mm     |
| CR050HD       | 336310        | Stål                            | Hot-Dip Galvanized | 15    | 20 - 25 mm          | 16 mm     |
| CR050S4       | 336410        | Stainless Steel 304 (EN 1.4301) |                    | 15    | 20 - 25 mm          | 16 mm     |
| CR075HD       | 336320        | Stål                            | Hot-Dip Galvanized | 20    | 26.9 - 31.8 mm      | 16 mm     |
| CR075S4       | 336420        | Stainless Steel 304 (EN 1.4301) |                    | 20    | 26.9 - 31.8 mm      | 16 mm     |


| Katalognummer | Artikelnummer | Materiale                       | Finish             | NB/DN | Outer Diameter (OD) | Width (W) |
|---------------|---------------|---------------------------------|--------------------|-------|---------------------|-----------|
| CR087HD       | 336322        | Stål                            | Hot-Dip Galvanized |       | 32 - 34 mm          | 16 mm     |
| CR100HD       | 336330        | Stål                            | Hot-Dip Galvanized | 25    | 33.7 - 38 mm        | 20 mm     |
| CR100S4       | 336430        | Stainless Steel 304 (EN 1.4301) |                    | 25    | 33.7 - 38 mm        | 20 mm     |
| CR125HD       | 336340        | Stål                            | Hot-Dip Galvanized | 32    | 40.0 - 44.5 mm      | 20 mm     |
| CR125S4       | 336440        | Stainless Steel 304 (EN 1.4301) |                    | 32    | 40.0 - 44.5 mm      | 20 mm     |
| CR150HD       | 336350        | Stål                            | Hot-Dip Galvanized | 40    | 47 - 51 mm          | 20 mm     |
| CR150S4       | 336450        | Stainless Steel 304 (EN 1.4301) |                    | 40    | 47 - 51 mm          | 20 mm     |
| CR200HD       | 336360        | Stål                            | Hot-Dip Galvanized | 50    | 59.2 - 63.5 mm      | 20 mm     |
| CR200S4       | 336460        | Stainless Steel 304 (EN 1.4301) |                    | 50    | 59.2 - 63.5 mm      | 20 mm     |

Table 2/2

| Katalognummer | Artikelnummer | Static Load 1 (F1) | Static Load 2 (F2) |
|---------------|---------------|--------------------|--------------------|
| CR037HD       | 336300        | 125N               | 550N               |
| CR037S4       | 336400        | 125N               | 550N               |
| CR050HD       | 336310        | 125N               | 550N               |
| CR050S4       | 336410        | 125N               | 550N               |
| CR075HD       | 336320        | 125N               | 550N               |
| CR075S4       | 336420        | 125N               | 550N               |
| CR087HD       | 336322        | 125N               | 550N               |

| Katalognummer | Artikelnummer | Static Load 1 (F1) | Static Load 2 (F2) |
|---------------|---------------|--------------------|--------------------|
| CR100HD       | 336330        | 250N               | 550N               |
| CR100S4       | 336430        | 250N               | 550N               |
| CR125HD       | 336340        | 250N               | 550N               |
| CR125S4       | 336440        | 250N               | 550N               |
| CR150HD       | 336350        | 250N               | 550N               |
| CR150S4       | 336450        | 250N               | 550N               |
| CR200HD       | 336360        | 250N               | 550N               |
| CR200S4       | 336460        | 250N               | 550N               |

## DIAGRAMS

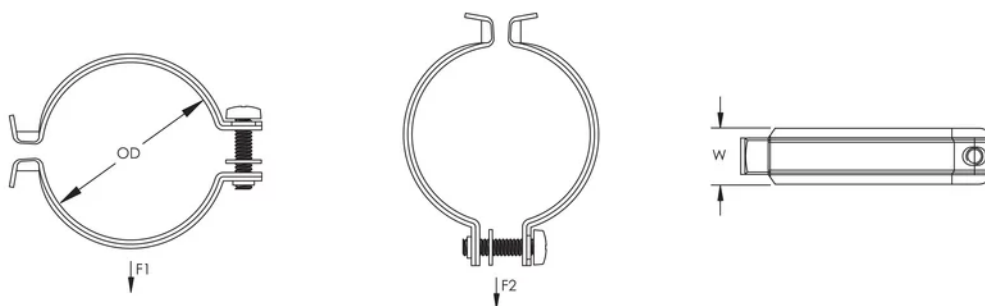

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

