

Strut Beam Clip



FUNKTIONER

Beam Clip for clamping the open side of strut to a beam

Suitable for all strut channels

Requires installation in pairs

Structural attachment to beams to support nVent CADDY Eristrut

FM® Specification Tested

SPECIFIKATIONER

Table 1/2

Katalognummer	Artikelnummer	Materiale	Finish	Flange Thickness (FT)	Hole Size (HS)	Length (L)
ZTA605	388080	Stål	Hot-Dip Galvanized	16 mm Max	13 mm	49mm
ZT605HD	313260	Stål	Hot-Dip Galvanized	16 mm Max	13 mm	49mm
ZTA605S6	387190	Stainless Steel 316 (EN 1.4401)		16 mm Max	13 mm	49mm

Table 2/2


Katalognummer	Artikelnummer	Thickness (T)	Width (W)	Static Load	Screw Included
ZTA605	388080	6 mm	40 mm	2040N	No

Katalognummer	Artikelnummer	Thickness (T)	Width (W)	Static Load	Screw Included
ZT605HD	313260	6 mm	40 mm	2040N	Yes
ZTA605S6	387190	6 mm	40 mm	2040N	No

YDERLIGERE PRODUKTOPLYSNINGER

Indicated loads are based on installation with 1/2" (M12) hardware and strut channel type A.

DIAGRAMS

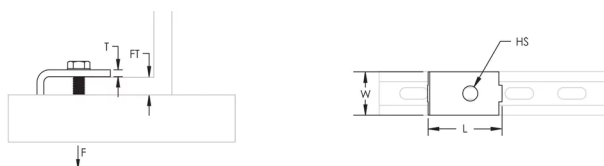

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

