

Telescoping Strut Replacement, Retrofit



FUNKTIONER

Slotted ends allow the bracket to be installed with four nVent CADDY SN Nuts on threaded rod above an existing trapeze, saving contractor time and limiting building downtime

Telescopes to the desired length and is locked in place by snapping closed a spring retainer clip

Standard strut profile runs the entire length of the part, allowing most standard fittings to be placed anywhere between the rods

Integrated ruler displays space between hanger rods in inches and centimeters

Supports up to seven 2" (50 DN) conduits, six 2" (50 DN) water filled pipes at 10' (3 m) spacing, or up to 18" (450 mm) cable tray

Conduit can be supported on the top and bottom, eliminating the need for double sided strut

Conduit and pipe can be placed directly on the strut profile, saving vertical space in buildings with limited room for installation

SPECIFIKATIONER

Table 1/3

Katalognummer	Artikelnummer	Materiale	Finish	Rod Size (RS)	Thickness (T)	A
TSR1220R	366594	Stål	Pregalvanized	10	1 mm	318 - 508 mm

Table 2/3


Katalognummer	Artikelnummer	B	C	D	E	Static Load 1 (F1)
TSR1220R	366594	356 - 546 mm	41 mm	22.2 mm	35 mm	1330N

Katalognummer	Artikelnummer	Static Load 2 (F2)
TSR1220R	366594	880N

YDERLIGERE PRODUKTOPLYSNINGER

Static Load 1 represents a distributed load for 12" - 20" (300 - 500 mm) installations and a point load for 12" - 16" (300 - 400 mm) installations. Static Load 2 represents a point load for 16" - 20" (400 - 500 mm) installations.

DIAGRAMS

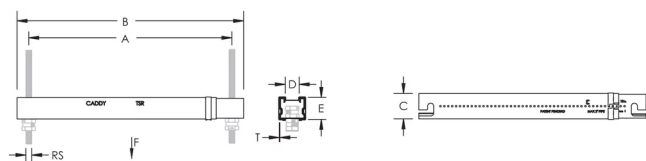

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

