


# Trapeze Sway Brace, Strut

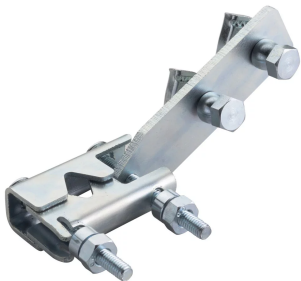

## CERTIFICERINGER



## FUNKTIONER

Seismically braces trapeze hangers

Retrofit ability allows for the brace to be installed after the trapeze assembly is installed

One wrench size fits all required hardware, eliminating the need to change tools

Shear-off head helps ensure correct torque and simplifies inspection

FM® Specification Tested

## SPECIFIKATIONER

Table 1/2

| Katalognummer | Artikelnummer | Materiale | Finish            | Rod Size (RS)  | Width (W) | Thickness (T) |
|---------------|---------------|-----------|-------------------|----------------|-----------|---------------|
| CSBR2         | 404567        | Stål      | Electrogalvanized | 10, 12, 16, 20 | 81.3 mm   | 3.4 mm        |

Table 2/2

| Katalognummer | Artikelnummer | A | B | C | D | E |
|---------------|---------------|---|---|---|---|---|
|---------------|---------------|---|---|---|---|---|


|       |        |          |         |       |         |         |
|-------|--------|----------|---------|-------|---------|---------|
| CSBR2 | 404567 | 133.4 mm | 86.4 mm | 29 mm | 47.8 mm | 41.1 mm |
|-------|--------|----------|---------|-------|---------|---------|

## YDERLIGERE PRODUKTOPLYSNINGER

Cut length for strut member is +/- 1" (25 mm) of measured length.

| FM Loads    |                       |                                                          |           |           |           |
|-------------|-----------------------|----------------------------------------------------------|-----------|-----------|-----------|
| Part Number | Brace Member          | Horizontal Capacity per Installation Angle from Vertical |           |           |           |
|             |                       | 30° - 44°                                                | 45° - 59° | 60° - 74° | 75° - 90° |
| CSBR2       | 41 x 41 Strut Channel | 4585 N                                                   | 8060 N    | 8895 N    | 9920 N    |

## DIAGRAMS

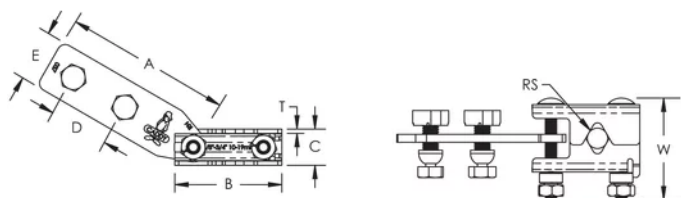

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

