

Uniklip Variable Riser



CERTIFICERINGER



FUNKTIONER

Creates a quick and easy vertical pathway transition

Provides optimal support for high-performance low voltage and data cables

Innovative UNIKLIP installation system that installs up to three times faster

IEC 61537 load rating and earthing compliant

No field cutting or modifications required; just drop it in and keep installing the cable tray

Eliminates safety related concerns around field cutting

Tool-free, integrated couplers with Uniklip

SPECIFIKATIONER

Finish: Pregalvanized

Materiale: Stål

Table 1/2

Katalognummer	Artikelnummer	Width (W)	Height (H)	Angle (a)	A	B
---------------	---------------	-----------	------------	-----------	---	---


PCT50X225VR90	850240	225 mm	437 mm	90 ° Max	296 mm	49 mm
PCT50X300VR90	850250	300 mm	437 mm	90 ° Max	296 mm	49 mm
PCT50X600VR90	850280	600 mm	437 mm	90 ° Max	296 mm	49 mm
PCT50X075VR90	850210	75 mm	437 mm	90 ° Max	296 mm	49 mm
PCT50X500VR90	850270	500 mm	437 mm	90 ° Max	296 mm	49 mm
PCT50X050VR90	850200	50 mm	437 mm	90 ° Max	296 mm	49 mm
PCT50X100VR90	850220	100 mm	437 mm	90 ° Max	296 mm	49 mm
PCT50X450VR90	850260	450 mm	437 mm	90 ° Max	296 mm	49 mm
PCT50X150VR90	850230	150 mm	437 mm	90 ° Max	296 mm	49 mm

Table 2/2

Katalognummer	Artikelnummer	C
PCT50X225VR90	850240	91 mm
PCT50X300VR90	850250	91 mm
PCT50X600VR90	850280	91 mm
PCT50X075VR90	850210	91 mm
PCT50X500VR90	850270	91 mm

Katalognummer	Artikelnummer	C
PCT50X050VR90	850200	91 mm
PCT50X100VR90	850220	91 mm
PCT50X450VR90	850260	91 mm
PCT50X150VR90	850230	91 mm

DIAGRAMS

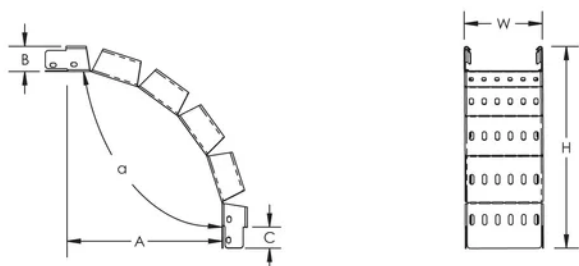

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

