

Universal Restraint Clip, Slotted



CERTIFICERINGER



FUNKTIONER

Slotted design ideal for attaching to existing threaded rod on trapezes

Meets CEN/TS 17551:2021 requirements for Seismic Sway Bracing

SPECIFIKATIONER

Finish: Electrogalvanized

Materiale: Stål

Table 1/1


Katalognummer	Artikelnummer	Brace Size	Rod Size (RS)	Thickness (T)
CSBURCR58	402203	#12, #18	16	4.27 mm
CSBURCR38	402201	#12, #18	10	4.27 mm
CSBURCR12	402202	#12, #18	12	4.27 mm

YDERLIGERE PRODUKTOPLYSNINGER

Brace member is not included.

UL Loads		
Part Number	Brace Member	Load Rating
CSBURCR38	CSB12CBL	1859 N
	CSB18CBL	3434 N
CSBURCR12	CSB12CBL	1859 N
	CSB18CBL	3434 N
CSBURCR58	CSB12CBL	1859 N
	CSB18CBL	3434 N

DIAGRAMS

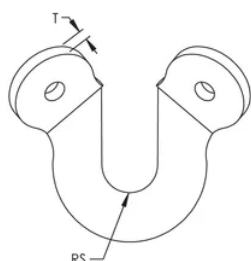

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

