

USC Universal Strut Clamp for Pipe/Conduit



FUNKTIONER

Consists of two clamps, nut and bolt

Fits into open side of strut channel

Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 59)

SPECIFIKATIONER

Materiale: Stål

Table 1/2

Katalognummer	Artikelnummer	Finish	Outer Diameter (OD)	NB/DN	Width (W)	Thickness (T)
USC021HD	712405	Hot-Dip Galvanized	20.5 - 21.4 mm	15	32 mm	1.5 mm
USC021EG	712045	Electrogalvanized	20.5 - 21.4 mm	15	32 mm	1.5 mm
USC020EG	712040	Electrogalvanized	17.9 - 20 mm		32 mm	1.5 mm
USC026HD	712422	Hot-Dip Galvanized	25.4 - 26.9 mm	20	32 mm	1.5 mm
USC026EG	712065	Electrogalvanized	25.4 - 26.9 mm	20	32 mm	1.5 mm
USC025EG	712060	Electrogalvanized	23.4 - 25.4 mm		32 mm	1.5 mm

Katalognummer	Artikelnummer	Finish	Outer Diameter (OD)	NB/DN	Width (W)	Thickness (T)
USC022EG	712050	Electrogalvanized	21.5 - 22.2 mm		32 mm	1.5 mm
USC033HD	712428	Hot-Dip Galvanized	32.8 - 33.4 mm		32 mm	1.5 mm
USC033EG	712085	Electrogalvanized	32.8 - 33.4 mm		32 mm	1.5 mm
USC031EG	712080	Electrogalvanized	29.5 - 32 mm		32 mm	1.5 mm
USC028EG	712070	Electrogalvanized	27.9 - 28.9 mm		32 mm	1.5 mm
USC040EG	712100	Electrogalvanized	38.4 - 40.6 mm		32 mm	2 mm
USC036EG	712090	Electrogalvanized	33.7 - 38.1 mm	25	32 mm	2 mm
USC042EG	712105	Electrogalvanized	41.3 - 42.4 mm	32	32 mm	2 mm
USC060EG	712035	Electrogalvanized	59.5 - 62.2 mm	50	32 mm	2.5 mm
USC060HD	712465	Hot-Dip Galvanized	59.5 - 62.2 mm	50	32 mm	2.5 mm
USC053EG	712120	Electrogalvanized	50.3 - 53.7 mm		32 mm	2.5 mm
USC048HD	712452	Hot-Dip Galvanized	47.6 - 50 mm	40	32 mm	2 mm
USC218EG	712340	Electrogalvanized	215.9 - 219.1 mm	200	32 mm	3 mm
USC048EG	712115	Electrogalvanized	47.6 - 50 mm	40	32 mm	2 mm
USC046EG	712110	Electrogalvanized	43 - 45 mm		32 mm	2 mm
USC113EG	712220	Electrogalvanized	111.1 - 115.3 mm	100	32 mm	2.5 mm
USC042HD	712445	Hot-Dip Galvanized	41.3 - 42.4 mm	32	32 mm	2 mm
USC159EG	712280	Electrogalvanized	155.6 - 162 mm		32 mm	3 mm

Katalognummer	Artikelnummer	Finish	Outer Diameter (OD)	NB/DN	Width (W)	Thickness (T)
USC086EG	712180	Electrogalvanized	84.0 - 88.9 mm	80	32 mm	2.5 mm
USC076EG	712165	Electrogalvanized	75.3 - 76.2 mm	65	32 mm	2.5 mm
USC277HD	712530	Hot-Dip Galvanized	273 - 280 mm	250	32 mm	3 mm
USC101EG	712200	Electrogalvanized	98.4 - 102.6 mm	90	32 mm	2.5 mm
USC073EG	712160	Electrogalvanized	69.9 - 73 mm		32 mm	2.5 mm
USC086HD	712480	Hot-Dip Galvanized	84.0 - 88.9 mm	80	32 mm	2.5 mm
USC076HD	712475	Hot-Dip Galvanized	75.3 - 76.2 mm	65	32 mm	2.5 mm
USC063EG	712140	Electrogalvanized	62.3 - 64.5 mm		32 mm	2.5 mm
USC168EG	712290	Electrogalvanized	165.1 - 171.5 mm	150	32 mm	3 mm
USC143EG	712260	Electrogalvanized	139.7 - 146.1 mm	125	32 mm	3 mm


Table 2/2

Katalognummer	Artikelnummer	Static Load
USC021HD	712405	2000N
USC021EG	712045	2000N
USC020EG	712040	2000N
USC026HD	712422	2000N
USC026EG	712065	2000N
USC025EG	712060	2000N
USC022EG	712050	2000N

Katalognummer	Artikelnummer	Static Load
USC033HD	712428	2000N
USC033EG	712085	2000N
USC031EG	712080	2000N
USC028EG	712070	2000N
USC040EG	712100	2670N
USC036EG	712090	2670N
USC042EG	712105	2670N
USC060EG	712035	3780N
USC060HD	712465	3780N
USC053EG	712120	3780N
USC048HD	712452	2670N
USC218EG	712340	4000N
USC048EG	712115	2670N
USC046EG	712110	2670N
USC113EG	712220	3780N
USC042HD	712445	2670N
USC159EG	712280	4000N
USC086EG	712180	3780N

Katalognummer	Artikelnummer	Static Load
USC076EG	712165	3780N
USC277HD	712530	4000N
USC101EG	712200	3780N
USC073EG	712160	3780N
USC086HD	712480	3780N
USC076HD	712475	3780N
USC063EG	712140	3780N
USC168EG	712290	4000N
USC143EG	712260	4000N

DIAGRAMS

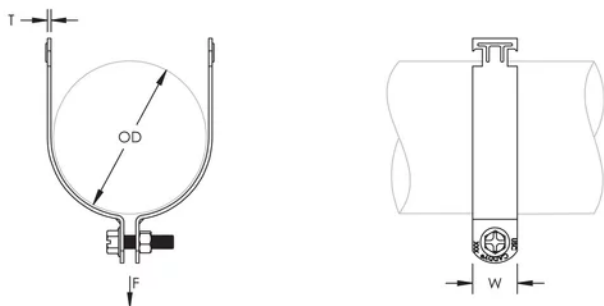

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

