

# 19" Front Panel With Holes for Handles

## Data Solutions



Define the device fronts and side inss with Schroff 19" front panels. Schroff 19" front panels have additional holes for mounting of handles and are available in 1 U to 6 U demensions.

### CERTIFICERINGER



### FUNKTIONER

19" front panels have additional holes for mounting of handles

### SPECIFIKATIONER

<b>Rack Width:</b>	95HP
<b>Materiale:</b>	Aluminium
<b>Accessory Type:</b>	Front panel
<b>Product Type:</b>	Front Panel

Table 1/3

Katalognummer	Rack Height	Dybde (D)	Håndtagstype	Finish	Mounting	Pakke mængde
30219-161	1U	3mm	Front Handle	Anodized	Screw-on Front	1

Katalognummer	Rack Height	Dybde (D)	Håndtagstype	Finish	Mounting	Pakke mængde
40304-050	1U	3mm	Front Handle	Anodized	Screw-on Front	1
30219-162	2U	3mm	Front Handle	Anodized	Screw-on Front	1
30219-163	3U	3mm	Front Handle	Anodized	Screw-on Front	1
30219-164	4U	3mm	Front Handle	Anodized	Screw-on Front	1
30219-165	5U	3mm	Front Handle	Anodized	Screw-on Front	1
30219-166	6U		Front Handle	Anodized	Screw-on Front	1
40304-051	2U	3mm	Front Handle	Anodized	Screw-on Front	1
40304-052	3U	3mm	Front Handle	Anodized	Screw-on Front	1
40304-053	4U	3mm	Front Handle	Anodized	Screw-on Front	1
40304-054	5U	3mm	Front Handle	Anodized	Screw-on Front	1
40304-055	6U	3mm	Front Handle	Anodized	Screw-on Front	1

Table 2/3						
Katalognummer	Front Finish	Rear Finish	Treated Edges	EMC Shielding	Højde (H)	Type
30219-161	Anodized	Anodized	No	No	43.6mm	19" Front Panel
40304-050	Anodized	Anodized	Yes	No	43.6mm	19" Front Panel
30219-162	Anodized	Anodized	No	No	88.1mm	19" Front Panel
30219-163	Anodized	Anodized	No	No	132.5mm	19" Front Panel
30219-164	Anodized	Anodized	No	No	177mm	19" Front Panel


Katalognummer	Front Finish	Rear Finish	Treated Edges	EMC Shielding	Højde (H)	Type
30219-165	Anodized	Anodized	No	No	221.4mm	19" Front Panel
30219-166	Anodized	Anodized	No	No	265.9mm	19" Front Panel
40304-051	Anodized	Anodized	Yes	No	88.1mm	19" Front Panel
40304-052	Anodized	Anodized	Yes	No	132.5mm	19" Front Panel
40304-053	Anodized	Anodized	Yes	No	177mm	19" Front Panel
40304-054	Anodized	Anodized	Yes	No	221.4mm	19" Front Panel
40304-055	Anodized	Anodized	Yes	No	265.9mm	19" Front Panel

Table 3/3

Katalognummer	Bredde (W)
30219-161	483mm
40304-050	483mm
30219-162	483mm
30219-163	483mm
30219-164	483mm
30219-165	483mm
30219-166	483mm
40304-051	483mm
40304-052	483mm
40304-053	483mm

Katalognummer	Bredde (W)
40304-054	483mm
40304-055	483mm

## DIAGRAMS

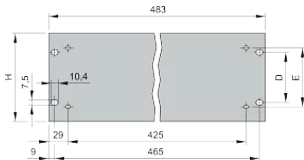

## ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**