


19" Front Panel, Vented

Data Solutions

Vented front panels allows heat dissipation through holes.

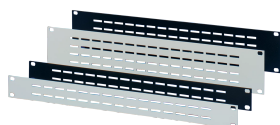

CERTIFICERINGER



FUNKTIONER

Vented front panels (Aluminum) allows heat dissipation

SPECIFIKATIONER

| | |
|------------------------|-------------|
| Rack Width: | 95HP |
| Materiale: | Aluminium |
| Accessory Type: | Front panel |
| Product Type: | Front Panel |

Table 1/2

| Katalognummer | Rack Height | Finish | Mounting | Pakke mængde | Front Finish | Rear Finish |
|---------------|-------------|--------------------------|----------------|--------------|--------------|-------------|
| 30118-962 | 1U | Struktur Pulvermaling | Screw-on Front | 1 | Painted | Painted |

| Katalognummer | Rack Height | Finish | Mounting | Pakke mængde | Front Finish | Rear Finish |
|---------------|-------------|-----------------------|----------------|--------------|--------------|-------------|
| 30702-044 | 1U | Anodized | Screw-on Front | 1 | Raw | Conductive |
| 30702-047 | 1U | Anodized | Screw-on Front | 1 | Anodized | Anodized |
| 30702-056 | 1U | Struktur Pulvermaling | Screw-on Front | 1 | Painted | Painted |
| 30118-963 | 2U | Anodized | Screw-on Front | 1 | Painted | Painted |
| 30118-964 | 3U | Struktur Pulvermaling | Screw-on Front | 1 | Painted | Painted |
| 30702-045 | 2U | Anodized | Screw-on Front | 1 | Raw | Raw |
| 30702-046 | 3U | Anodized | Screw-on Front | 1 | Raw | Raw |
| 30702-048 | 2U | Anodized | Screw-on Front | 1 | Anodized | Anodized |
| 30702-049 | 3U | Anodized | Screw-on Front | 1 | Anodized | Anodized |
| 30702-057 | 2U | Struktur Pulvermaling | Screw-on Front | 1 | Painted | Painted |
| 30702-058 | 3U | Struktur Pulvermaling | Screw-on Front | 1 | Painted | Painted |


| Table 2/2 | | | | | | |
|---------------|---------------|-----------|---------------|-----------|-----------------|------------|
| Katalognummer | Treated Edges | Farvekode | EMC Shielding | Højde (H) | Type | Bredde (W) |
| 30118-962 | | RAL 7021 | No | 43.6mm | 19" Front Panel | 483mm |
| 30702-044 | | | No | 43.6mm | 19" Front Panel | 483mm |
| 30702-047 | Yes | | No | 43.6mm | 19" Front Panel | 483mm |
| 30702-056 | | RAL 7035 | No | 43.6mm | 19" Front Panel | 483mm |
| 30118-963 | | RAL 7021 | No | 88.1mm | 19" Front Panel | 483mm |

| Katalognummer | Treated Edges | Farvekode | EMC Shielding | Højde (H) | Type | Bredde (W) |
|---------------|---------------|-----------|---------------|-----------|-----------------|------------|
| 30118-964 | | RAL 7021 | No | 132.5mm | 19" Front Panel | 483mm |
| 30702-045 | | | No | 88.1mm | 19" Front Panel | 483mm |
| 30702-046 | | | No | 132.5mm | 19" Front Panel | 483mm |
| 30702-048 | Yes | | No | 88.1mm | 19" Front Panel | 483mm |
| 30702-049 | Yes | | No | 132.5mm | 19" Front Panel | 483mm |
| 30702-057 | | RAL 7035 | No | 88.1mm | 19" Front Panel | 483mm |
| 30702-058 | | RAL 7035 | No | 132.5mm | 19" Front Panel | 483mm |

YDERLIGERE PRODUKTOPLYSNINGER

Please order 19" assembly kit separately.

DIAGRAMS

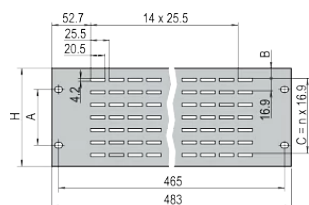

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE