

Branch Line Restraint Structure Attachment to Steel

Data Solutions



CERTIFICERINGER



FUNKTIONER

Swivel barrel nut accepts 3/8" or 1/2" (M10 or M12) threaded rod

Attaches to steel members with self-drilling/tapping screw

SPECIFIKATIONER

Table 1/2

Katalognummer	Artikelnummer	Materiale	Finish	Rod Size (RS)	Flange Thickness (FT)	Height (H)
CSBBRS1MEG	402239	Stål	Electrogalvanized	10, 12	2.7 – 12.7mm	28.2mm

Table 2/2


Katalognummer	Artikelnummer	Length (L)	Width (W)	Screw Diameter (Sc)	Screw Length (L)
---------------	---------------	------------	-----------	---------------------	------------------

CSBBRS1MEG	402239	40.4mm	26.9mm	2.7mm	32mm
------------	--------	--------	--------	-------	------

YDERLIGERE PRODUKTOPLYSNINGER

Branch line structural attachments are for restraint only and not for the hanging of fire sprinkler piping.

DIAGRAMS

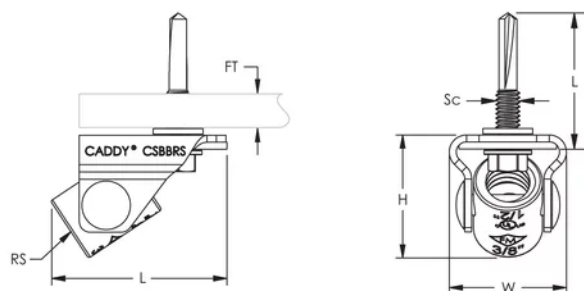

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE