

Branch Line Restraint Structure Attachment to Wood/Concrete

Data Solutions



CERTIFICERINGER



FUNKTIONER

Swivel barrel nut accepts 3/8" or 1/2" (M10 or M12) threaded rod

Attaches to wood or concrete where cracked concrete approval is not needed

SPECIFIKATIONER

Table 1/2

Katalognummer	Artikelnummer	Materiale	Finish	Rod Size (RS)	Height (H)	Length (L)
CSBBRS2MEG	402240	Stål	Electrogalvanized	10, 12	28.2mm	40.4mm

Table 2/2


Katalognummer	Artikelnummer	Width (W)	Screw Length (L)	Drill Bit Diameter
---------------	---------------	-----------	------------------	--------------------

CSBBRS2MEG	402240	26.9mm	44.5mm	5mm
------------	--------	--------	--------	-----

YDERLIGERE PRODUKTOPLYSNINGER

Branch line structural attachments are for restraint only and not for the hanging of fire sprinkler piping.

DIAGRAMS

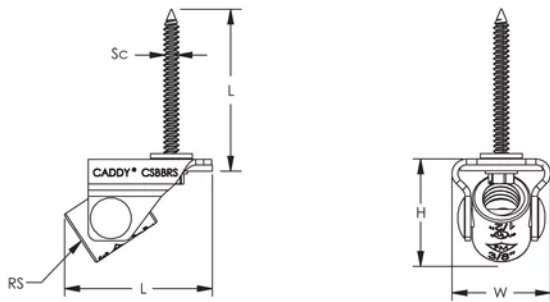

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE