


Electrical Earth Bar, Bare, 4 Connections, 1 Number of Disconnects, 375 mm

Data Solutions

KATALOGNUMMER

EEB04C506D1A

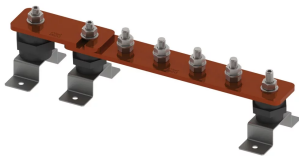

FUNKTIONER

Provides a convenient, single-point grounding and bonding location

Busbars with disconnect links allow for convenient testing of the earth termination system

High conductivity, hard drawn, electrolytic tough pitch copper per EN 13601

Includes halogen-free polyamide insulators, stainless steel (EN 1.4401) hardware and mounting brackets

Custom bars can be designed and manufactured to customer specifications

PRODUKTEGENSKABER

Complies With: IEC® EN 62561-1:2017 Class H

Materiale: Copper

Finish: Bare

Number of Connections: 4

Number of Disconnects: 1

Thread Size (TS): M10

Height (H): 94mm

Length (L): 375mm

Width 1 (W1): 100mm

Width 2 (W2): 50mm

Thickness (T): 6mm

 
A: 50mm

Unit Weight: 2.06kg

YDERLIGERE PRODUKTOPLYSNINGER

Tinned finish is 8 microns according to ASTM B545 Service Class "C" for corrosive environments.

DIAGRAMS



ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE