

Stud to Web of Rail Kit, RI52, RI59, 49.27 mm, 9.5 mm dia, 3/8 UNC Thread

Data Solutions

KATALOGNUMMER

PBK244



FUNKTIONER

Provides material to directly connect studs to the neutral axis of the rail web utilizing the exothermic process

Kits include an nVent ERICO Cadweld mold allocation, mold cleaning tool, flint ignitor, studs, washers and nuts

PRODUKTEGENSKABER

Materiale: Graphite; Silicon Bronze; Stainless Steel 302 (EN 1.4324); Stainless Steel 304 (EN 1.4301)

Rail Type: RI52; RI59

Number of Connections: 1

Minimum Order Quantity: 50

Mold Family: HV Mold Family

Length (L): 49.27mm

Diameter (Ø): 9.5mm

Thread Size (TS): 3/8" UNC

Studs: Stainless Steel (1)

Washers: 3/8" Silicon Bronze Lock Washer (1)

Nuts: 3/8"-16 UNC Silicon Bronze Hex Nut (1)

Mold Only: No

Replacement Mold: PBHV12A003

Welding Material: PB65, Sold Separately

Handle Clamp: L160, Sold Separately


Kit: Yes

YDERLIGERE PRODUKTOPLYSNINGER

Welder frame sold separately.

A gap between conductors may be required. See mold tag for more information.

DIAGRAMS

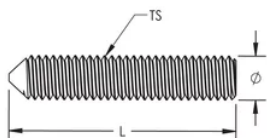

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer.

Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE