


# Varistar CP 19" Panel/Slide Mount, RAL 9005, 47 U, 2200H

## Data Solutions

### KATALOGNUMMER

**24630-014**

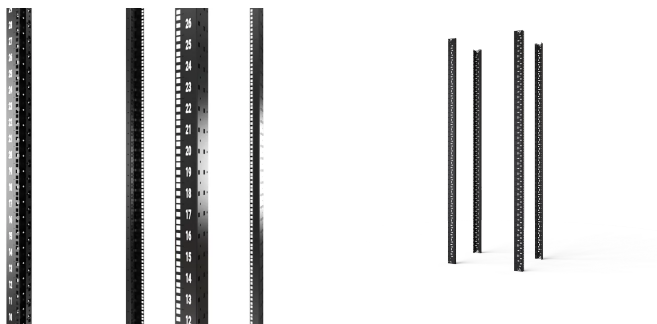

Slide mount with adjustable increments. Assembly in 600 mm wide cabinets directly on the frame. At 800 mm width adapter bracket for reduced width is necessary, for partial-height mounting depth members are necessary.

### FUNKTIONER

19" panel/slide mount with U indicator

Depth-adjustable in 25 mm increments

In accordance with IEC 60297-1 (DIN 41 494, Part 1)

### PRODUKTEGENSKABER

Rack Height: 47U

Højde: 2200mm

Pakke mængde: 4

Farve: Jet Black

Farvekode: RAL 9005

Finish: Struktur Pulvermaling

Materiale: Stål

Produktfamilie: Varistar CP

Product Type: Slide Mount

Net Weight: 19.338kg

## ADVARSEL

---

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på [www.nvent.com](http://www.nvent.com) og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**