


Joint Bond T8 Complete Welder Pair, Power

Data Solutions

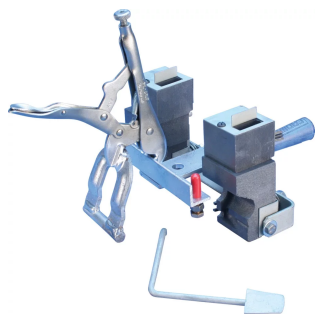

FUNKTIONER

Complete welder assembly provides a convenient means of attaching jumper bonds to the head of the rail

Connection is made within the confines of the splice plate

Includes mold cleaner and flint ignitor

SPECIFIKATIONER

Rail Type: 85 lb to 141 lb T-Rail Sections

Bond Terminal Style: C

Materiale: Graphite; Stål; Thermoplastic

Table 1/1

Katalognummer	Artikelnummer	Conductor Size	Conductor Outer Diameter, Nominal	Bond Length	Welder Style
PBCT8X3		50 mm ² Ropelay	9.13mm	177.8mm	T8
PBCT8X6	224422	120 mm ² Ropelay	9.53mm	177.8mm	T8
PBCT82S13		2/0 Concentric	10.62mm	330.2mm	T8
PBCT82J13		2/0 Ropelay	12.19mm	330.2mm	T8

Katalognummer	Artikelnummer	Conductor Size	Conductor Outer Diameter, Nominal	Bond Length	Welder Style
PBCT82J9		2/0 Ropelay	12.19mm	228.6mm	T8
PBCT8S6A13		3/0 Composite	14.53mm	330.2mm	T8
PBCT82S9		4/0 Ropelay	15.49mm	228.6mm	T8
PBCT8Y5X5		95 mm ² Ropelay	15.52mm	177.8mm	T8
PBCT82W13		250 kcmil Ropelay	19.05mm	330.2mm	T8

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.

⚠ WARNING: This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.ca.gov.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE