

nVent ERIFLEX Flexbus HCBC Plate with PE Connection

Data Solutions



CERTIFICERINGER



FUNKTIONER

Rigid tinned copper part provides strong electrical contact to maintain braid expansion during compression

HCBC Plate allows Flexbus Conductor insulation to overlap the connection palm

HCBC Plate with PE connection allows conductor to be added to interconnect neutral and ground/earth

Tinned copper allows for copper or aluminum conductor connections

Installs quickly and easily

RoHS compliant

SPECIFIKATIONER

Materiale: Copper

Finish: Tinned

Table 1/2

Katalognummer	Artikelnummer	A	B	C	D	E
FLEXPLATE50PE	508182	65mm	100mm	45mm	41mm	70mm
FLEXPLATE100PE	508183	115mm	100mm	45mm	51mm	70mm


Table 2/2

Katalognummer	Artikelnummer	Hole Size 1 (HS1)	Hole Size 2 (HS2)	Thickness (T)	Conductor Size	Unit Weight
FLEXPLATE50PE	508182	10.5mm	14.5mm	5mm	220 mm ² , 360 mm ² , 545 mm ² , 640 mm ²	0.49kg
FLEXPLATE100PE	508183	12.5mm	18.5mm	5mm	960 mm ² , 1280 mm ² , 1810 mm ²	0.71kg

YDERLIGERE PRODUKTOPLYSNINGER

It is mandatory to use the HCBC Clamp associated with the HCBC Plate for proper Flexbus Conductor connection.

DIAGRAMS

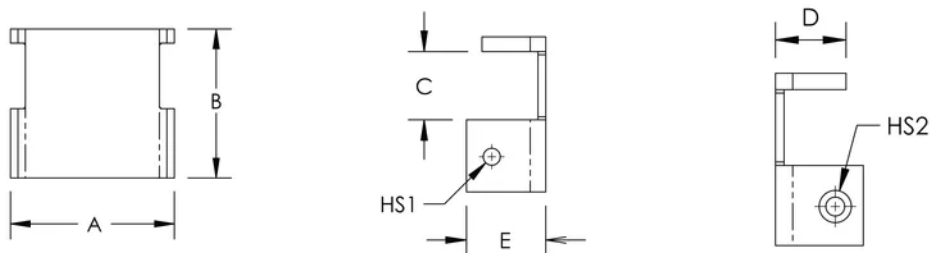

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE