

nVent ERIFLEX Flexbus HCBC Plate

Data Solutions



CERTIFICERINGER



FUNKTIONER

Rigid tinned copper part provides strong electrical contact to maintain braid expansion during compression

HCBC Plate allows Flexbus Conductor insulation to overlap the connection palm

Tinned copper allows for copper or aluminum conductor connections

Installs quickly and easily

RoHS compliant

SPECIFIKATIONER

Materiale: Copper

Finish: Tinned

Table 1/2

Katalognummer	Artikelnummer	A	B	C	D	Thickness (T)
---------------	---------------	---	---	---	---	---------------

FLEXPLATE50	508180	65mm	63mm	45mm	41mm	5mm
FLEXPLATE100	508181	115mm	63mm	45mm	51mm	5mm


Table 2/2

Katalognummer	Artikelnummer	Conductor Size	Unit Weight
FLEXPLATE50	508180	220 mm ² , 360 mm ² , 545 mm ² , 640 mm ²	0.16kg
FLEXPLATE100	508181	960 mm ² , 1280 mm ² , 1810 mm ²	0.32kg

YDERLIGERE PRODUKTOPLYSNINGER

It is mandatory to use the HCBC Clamp associated with the HCBC Plate for proper Flexbus Conductor connection.

DIAGRAMS

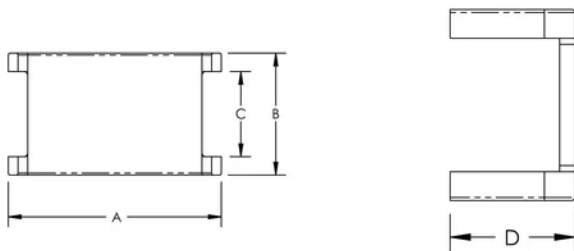

ADVARSEL

nVent-produkter skal kun installeres og anvendes som angivet i nVents produktvejledninger og træningsmaterialer. Vejledninger er tilgængelige på www.nvent.com og hos din nVent kundeservicerepræsentant. Forkert installation, misbrug, fejlanvendelse eller anden undladelse af fuldt ud at følge nVents instruktioner og advarsler kan medføre funktionsfejl, materielle skader, alvorlige personskader eller død og/eller ugyldiggøre din garanti.



Vores kraftfulde portefølje af mærker:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE